


1. SPECIFICATION

AK-3008B-2

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 30 mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.5 W for 1 minute	
05	Impedance	8 $\Omega \pm 15\%$ at 1 KHz 1V	
06	Resonance Frequency (Fo)	600 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	96 dB(1.0W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
08	Frequency Range	Fo – 6 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.0W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

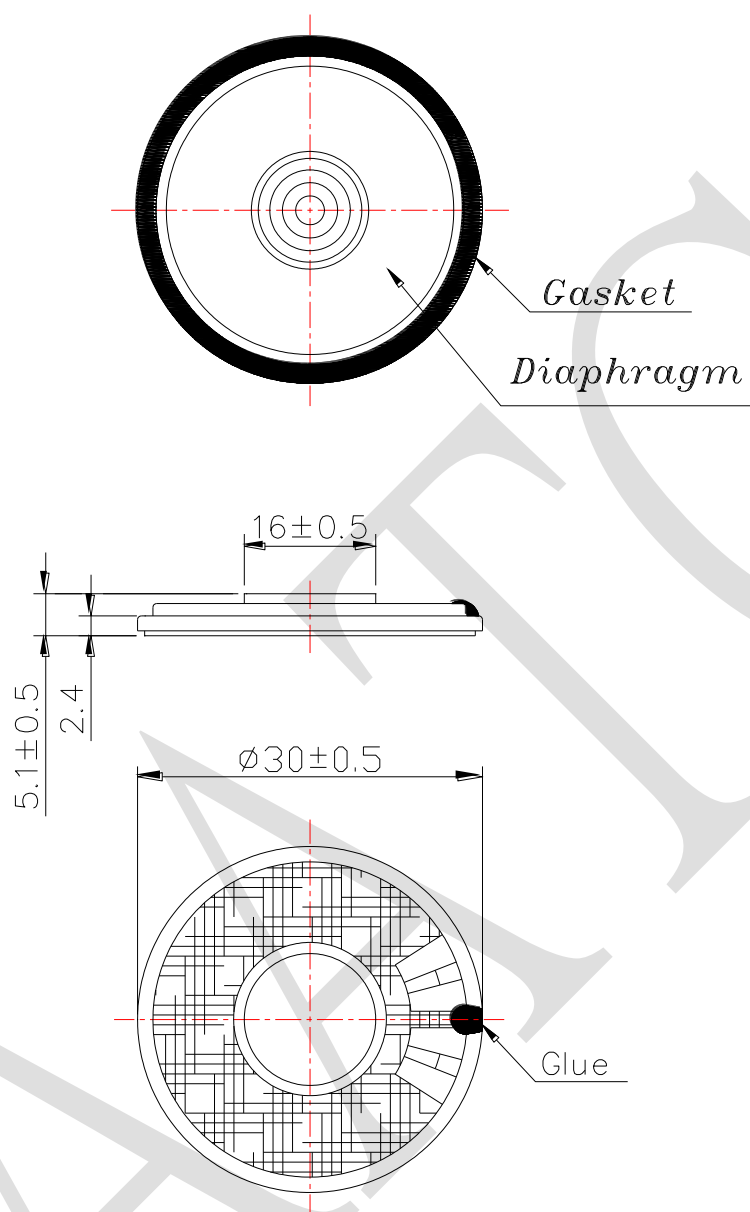

RoHS

TITLE: DYNAMIC SPEAKER		1	DRAWN: Zack	2015/03/19	SCALE: 2:1	SHEET: 1:1
PART NO. AK-3008B-2			DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. CXS30051-R08W1.0-E1			CHECKED:	TOLERANCE ± 0.5		
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		REV	MATERIAL: SPCC	ONE PLACE DECIMAL $\pm$ ***		
				TWO PLACE DECIMAL $\pm$ ***		
				THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-3008B-2](#)