

File Name:

AZ-4229S-FJ


Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	6~28	
03	Rated Current	mA(Max)	6	At 12 VDC
04	Sound Output At 30 cm	dBA(Min)	78	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Fast Pulse		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	35	

REV NO.

REVISION NOTE

APPROVAL

DATE

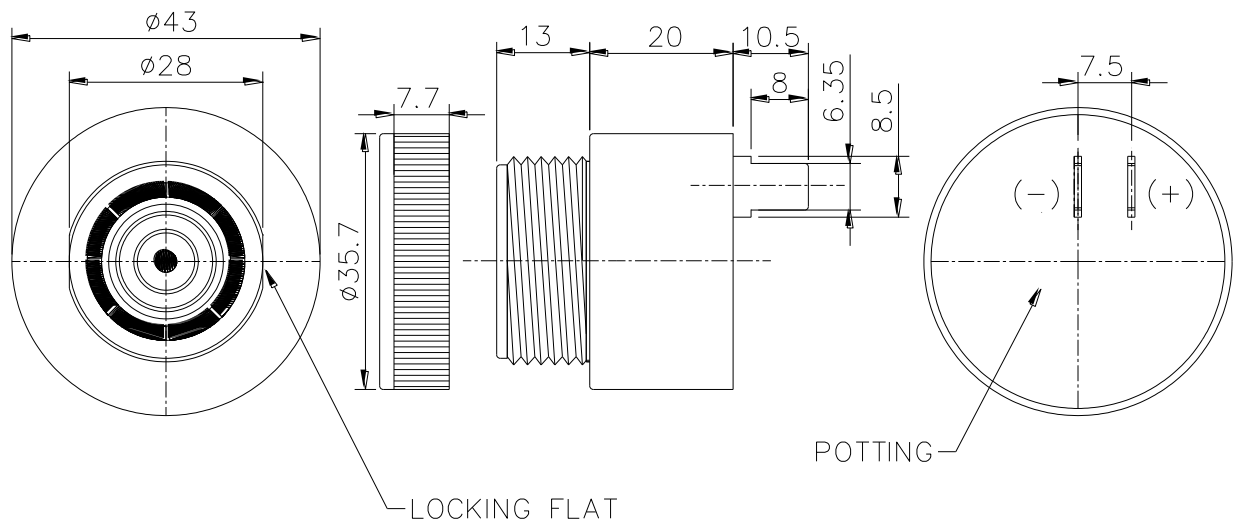

TITLE: <i>PIEZO BUZZER</i>		1 REV	DRAWN: <b>JOAN</b> 11/14/2001	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-4229S-FJ</i>			DESIGNED: <i>R &amp; D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>DTP-1107</i>			CHECKED:	TOLERANCE $\pm 0.5$ mm	
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
			MATERIAL: *****	ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



苙翔科技股份有限公司  
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4229S-FJ](#)