

1. SPECIFICATION

AK-1308DA-10W


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 13 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	0.8 W for 1 minute	
05	Impedance	8Ω ± 15% at 2KHz 1V	
06	Resonance Frequency (Fo)	1060 Hz ± 20% at Fo, 1V	
07	Sound pressure level	85 dB(0.1W/0.1M) ± 3 dB	at AVE 1.0, 1.2, 1.5, 2 KHz.
		90 dB(0.5W/.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.

REVISION NOTE

APPROVAL

DATE

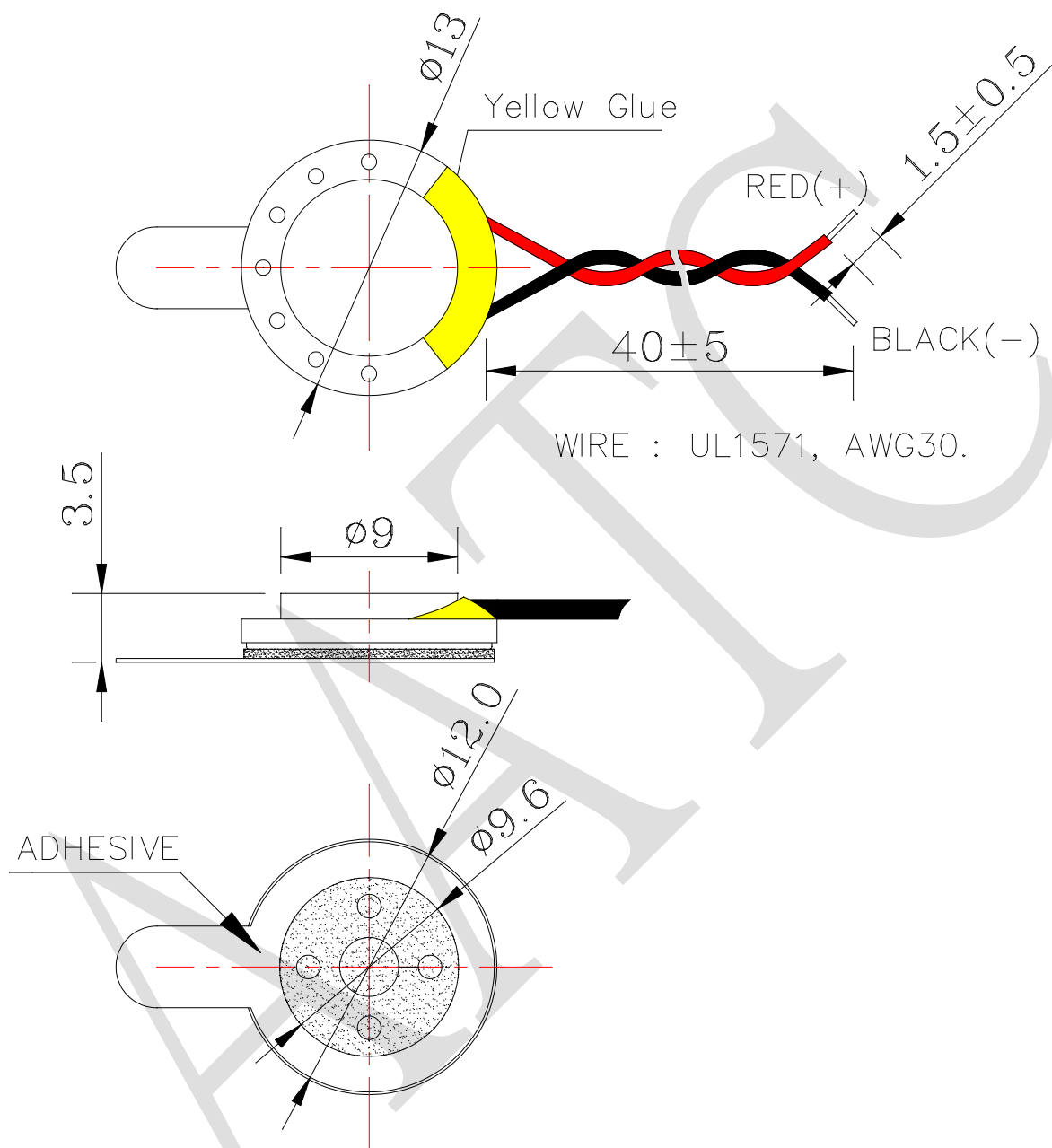

RoHS

TITLE: DYNAMIC RECEIVER		DRAWN: Sunny 2015/10/29	SCALE: 2:1	SHEET: 1 of 1
PART NO. AK-1308DA-10W		DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. ****		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: SPCC	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-1308DA-10W](#)