


1. SPECIFICATION

AK-36100025-PM-2

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter36 mm	
03	Rated Input Power	0.25 W	
04	Max. Input Power	0.5W for 1 minute	
05	Impedance	100 Ω $\pm$ 15%	
06	Resonance Frequency (Fo)	650 Hz $\pm$ 20% at Fo, 1V	
07	Sound pressure level	92 dB(0.25W/0.1M) $\pm$ 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
08	Frequency Range	Fo – 5 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz,0.1W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

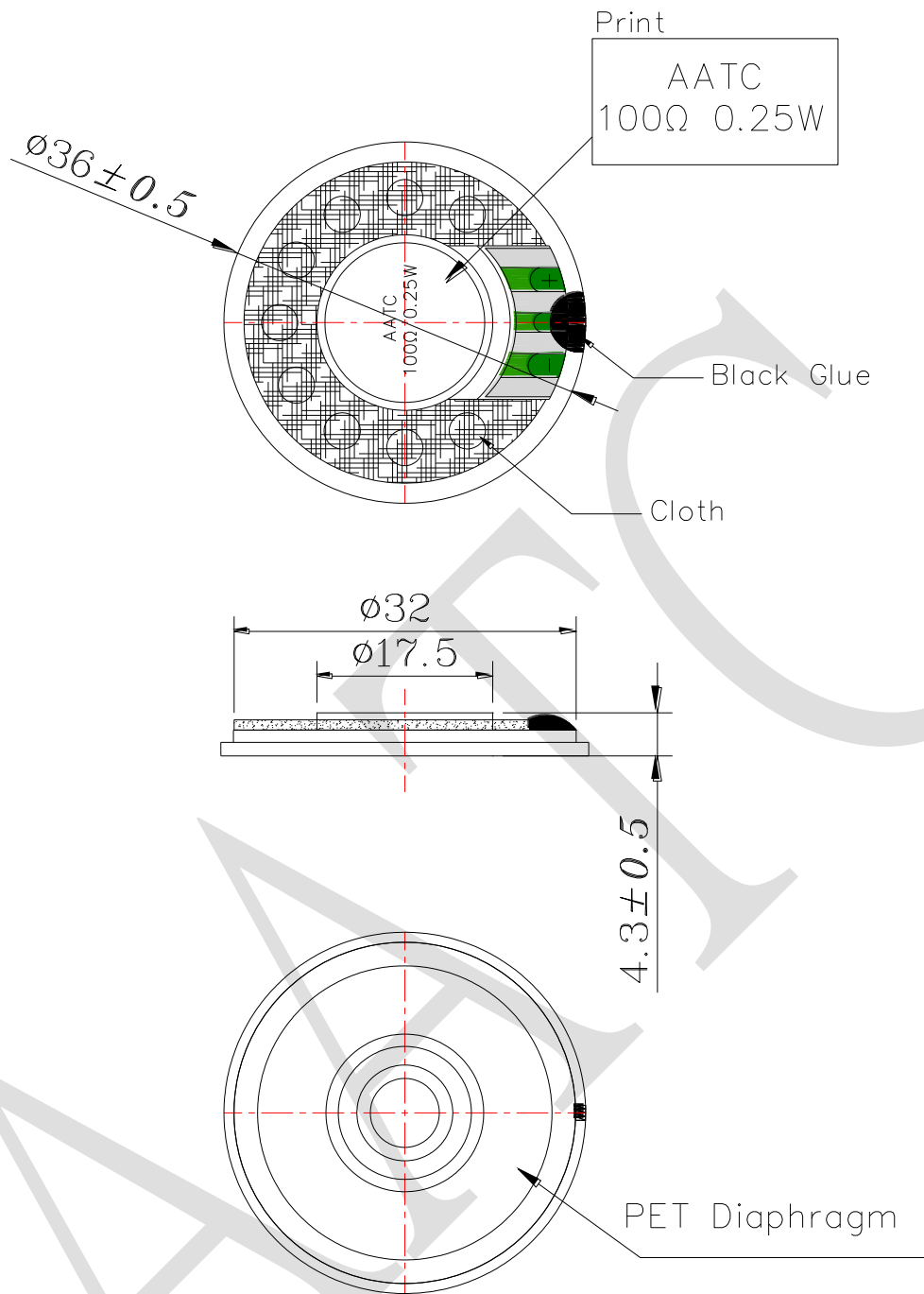

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Moose	2016-03-14	SCALE: 2:1	SHEET: 1:1
PART NO. AK-36100025-PM-2	1	DESIGNED: R&D OF AAT		UNITS: mm	
		CHECKED:		TOLERANCE ± 0.5	
DWG NO. CXS36043-R100W0.25-J	REV	APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: ABS		ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-36100025-PM-2](#)