


1. SPECIFICATION

AE-1540E-W1

| TYPE |                    | EXTERNAL -drive type sound element |                |                             |
|------|--------------------|------------------------------------|----------------|-----------------------------|
| ITEM |                    | UNITS                              | SPECIFICATIONS | CONDITIONS                  |
| 01   | Input Voltage      | V (Max)                            | 30             | Vp-p (Square Wave) 1/2 duty |
| 02   | Resonant Frequency | KHz                                | 4.0± 0.5       | at 25± 2℃ , 45~60% RH       |
| 03   | Resonant Impedance | Ω (Max)                            | 500            | at 25± 2℃ , 45~60% RH       |
| 04   | Capacitance        | pF                                 | 20000±30%      | At 120Hz                    |
| 05   | Plate Material     |                                    |                | BRASS                       |

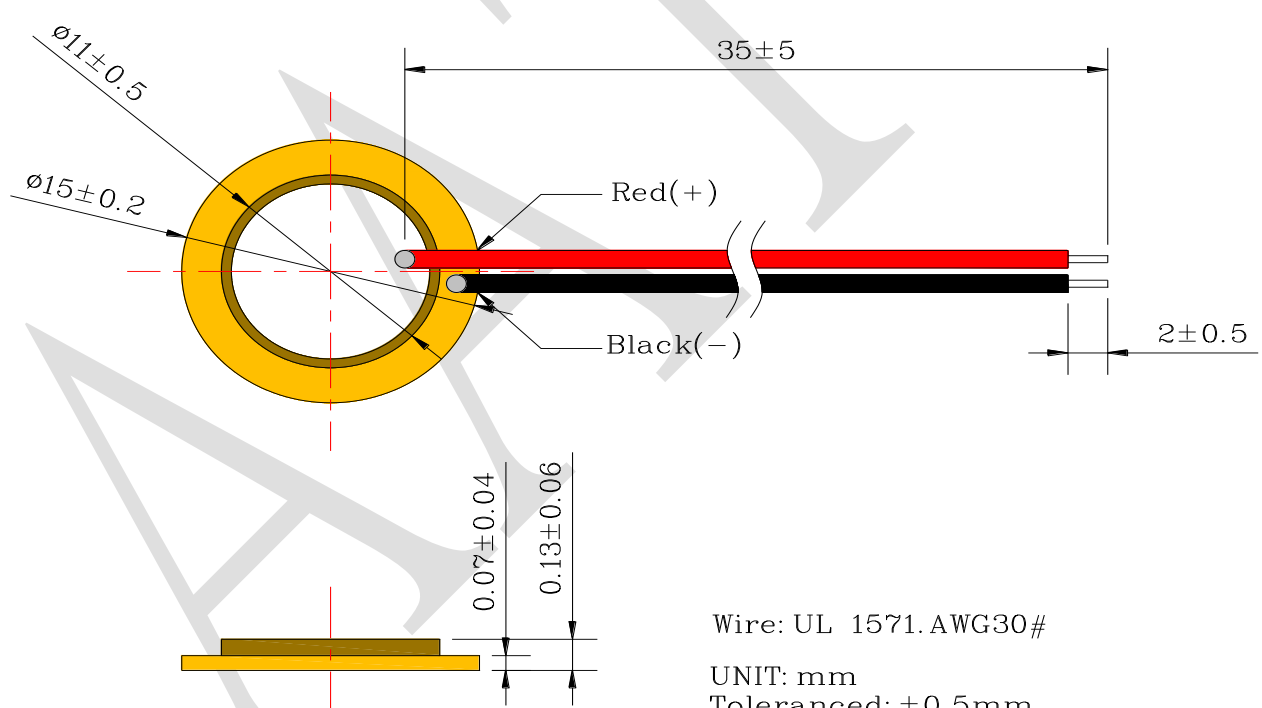

Wire: UL 1571.AWG30#  
UNIT: mm  
Toleranced:  $\pm 0.5$  mm



For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AE-1540E-W1](#)