


1. Specifications

AZ-4329S-GJB (RoHS)

Items		Units	Specifications	Conditions
01	Rated Voltage	VAC	110	
02	Operating Voltage	VDC / VAC	30 ~ 120	
03	Rated Current	mA(Max)	18	At 110 VAC
04	Sound Output at 30cm	dBA(Min)	80	At 110 VAC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Fast Pulse(3Hz)		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	43	

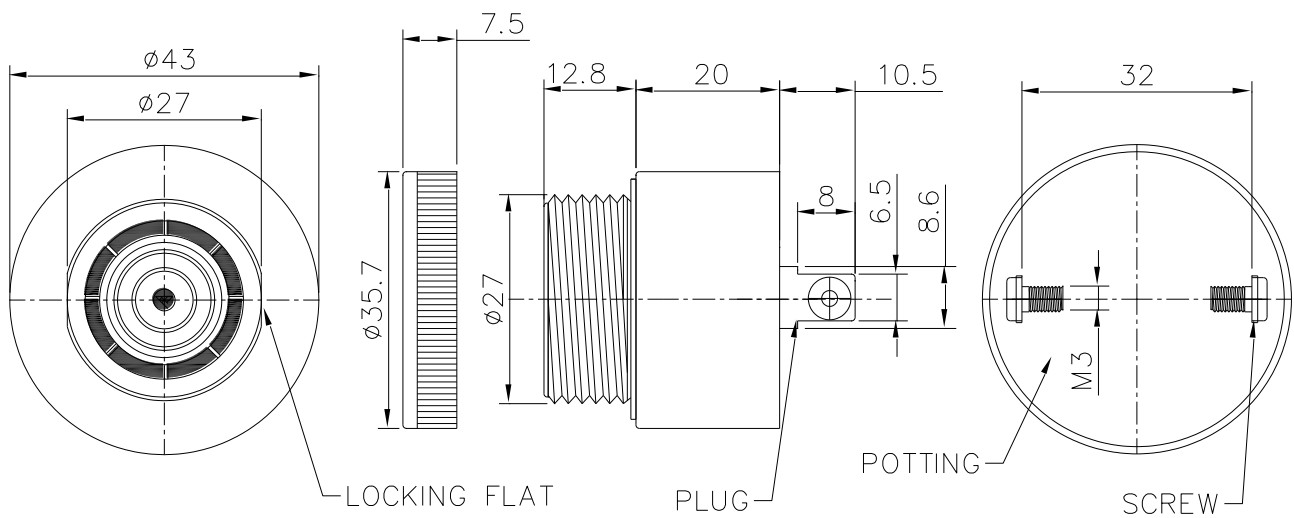

TITLE: <i>PIEZO BUZZER</i>		1	DRAWN: Jason 2009/06/25	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-4329S-GJB</i>			DESIGNED: R & D OF AAT	UNITS: mm	
			CHECKED:	TOLERANCE ± 0.5 mm	
DWG NO. <i>HS-09062501</i>	REV		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>Black ABS</i>	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4329S-GJB](#)