


File Name:

AZ-4329S-L

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	6~28	
03	Rated Current	mA(Max)	10	At 12 VDC
04	Sound Output At 30 cm	dBA(Min)	85	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Continuous		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	35	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

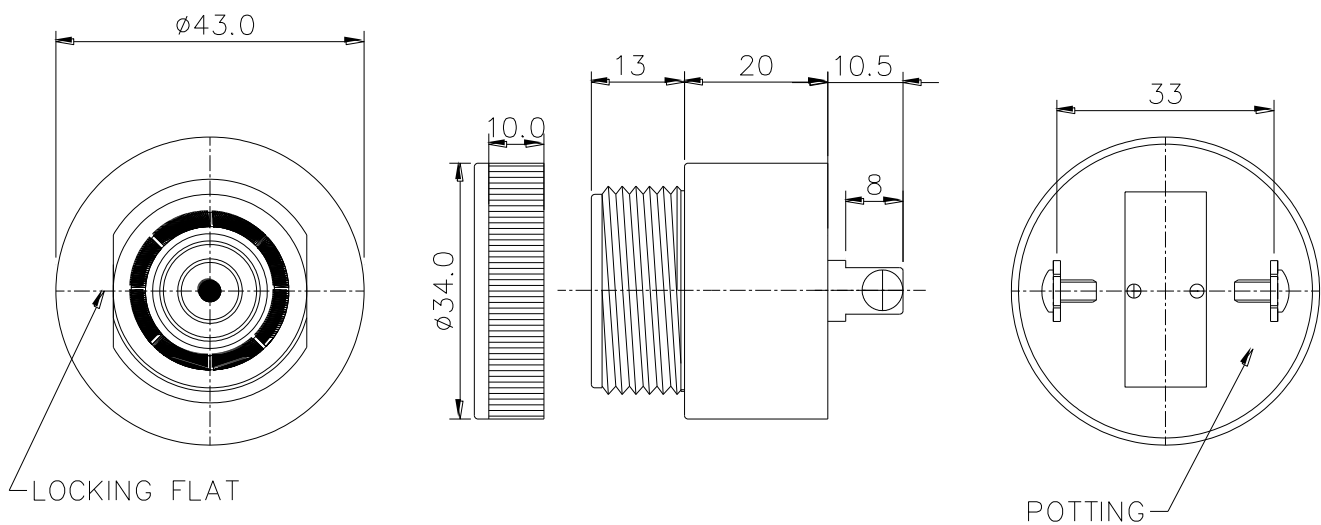

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <b>Milton</b>	10/09/2002	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-4329S-L</i>	1	DESIGNED: <i>R &amp; D OF AAT</i>	UNITS: <i>mm</i>		
DWG NO. <i>DTP-1189</i>		CHECKED:	TOLERANCE $\pm 0.5$ mm		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



**苙翔科技股份有限公司**  
**ADVANCED ACOUSTIC TECHNOLOGY CORPORATION**

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4329S-L](#)