


1. Specifications

SU2950SA

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12.0	
02	Operating Voltage	VDC	6~28	
03	Rated Current (Max)	mA	12	At 12VDC
04	Min Sound Output	dBA	95	At 12VDC / 30cm
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Single		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	36	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

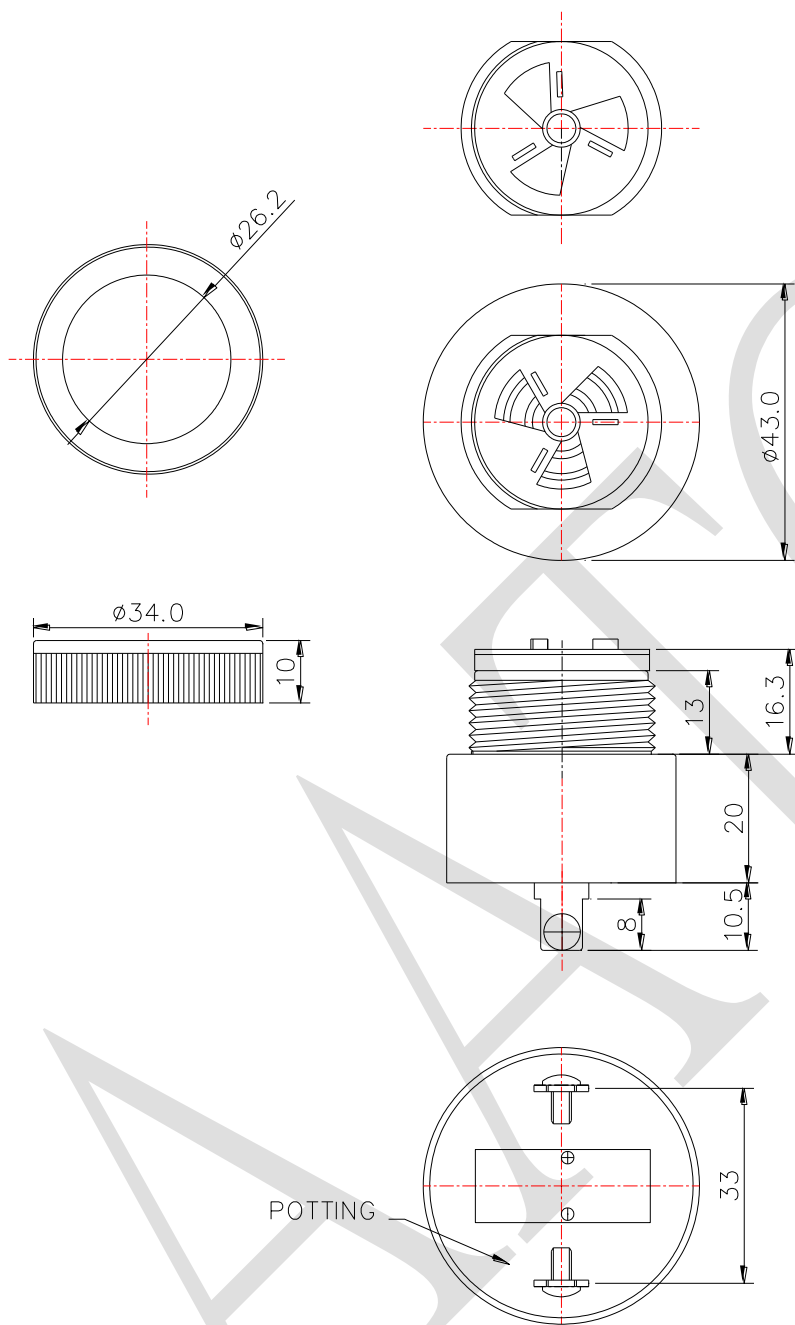

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <b>Moose</b> 08/03/2015	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>SU2950SA</i>	2 REV	DESIGNED: <i>R &amp; D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>DTP-1189</i>		CHECKED:	TOLERANCE $\pm 0.5$ mm	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[SU2950SA](#)