

1. SPECIFICATION

AR-13130A-1P



ITEM		SPECIFICATIONS
01	Type	Dynamic 13mm receiver unit
02	Sound pressure level	95 dB $\pm$ 3 dB at 1KHz 180mV with IEC318 coupler.
03	Impedance	130 $\Omega$ $\pm$ 15% at 1.0 KHz
04	Frequency Range	100 – 10K Hz
05	Rated Input Power	10 m W
06	Max. Input Power	20 m W
07	Total Harmonics Distortion	Max 10 % at 1 KHz,10 m W.

REV NO.




REVISION NOTE

APPROVAL


DATE

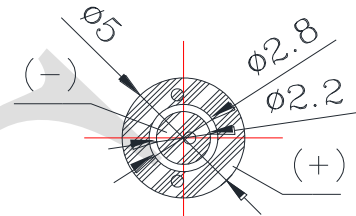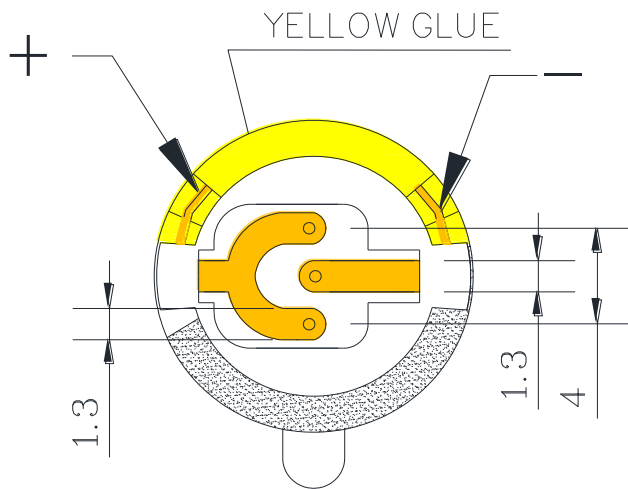

PCB LAYOUT

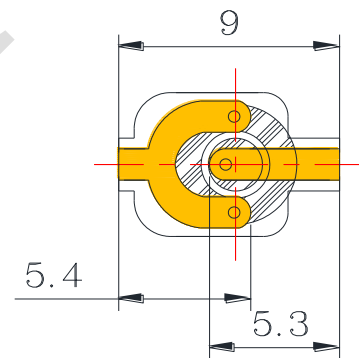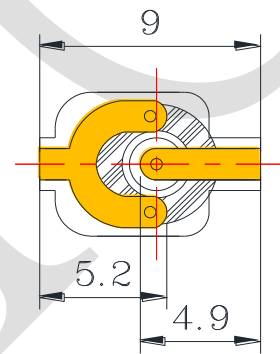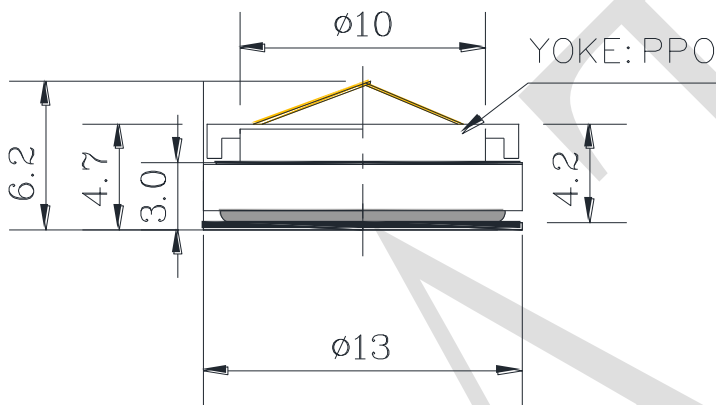

WORKING

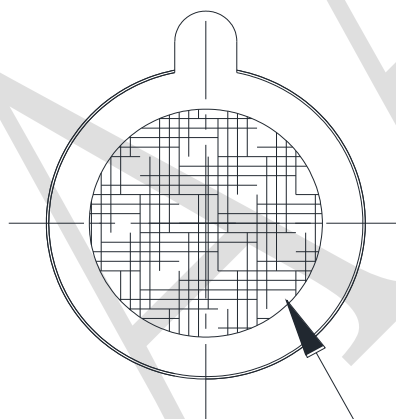

BLACK CLOTH

DIAPHRAGM: PET

RoHS

TITLE: DYNAMIC RECEIVER

DRAWN: Sunny 2013/12/26

SCALE: 2:1

SHEET: 1:1

PART NO. AR-13130A-1P

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

DWG NO. CZ-R2013122601

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV 1

MATERIAL: PBT/PET

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AR-13150A-1P