


1. SPECIFICATION

AK-360810-MM-3C

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 36 mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.5 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 1KHz 1V	
06	Resonance Frequency (Fo)	600 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	98 dB(1.0W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
08	Frequency Range	Fo – 5 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

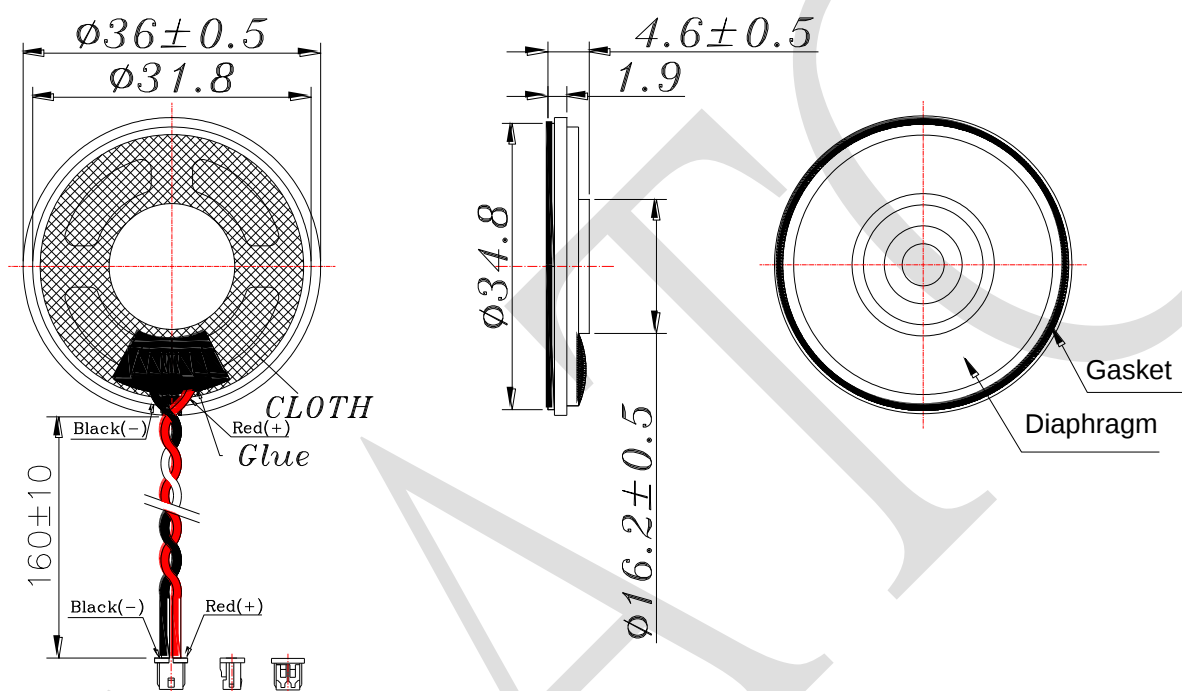

WIRE: UL1571,AWG28#

CONNECTOR :Equivalent to Molex 51021-0200

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2016/03/09	SCALE: 2:1	SHEET: 1:1
PART NO.	AK-360810-MM-3C	DESIGNED:	R&D OF AAT	UNITS:	mm
DWG NO.	CXS36046LP160-R08W1.0-C	CHECKED:		TOLERANCE	± 0.5
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL:	SPCC	ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-360810-MM-3C](#)