

1. SPECIFICATION

AK-400420-MM-1


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 40 mm	
03	Rated Input Power	2.0 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	4 Ω ± 15% at **KHz 1V	
06	Resonance Frequency (Fo)	600 Hz ± 20% at Fo, 1V	
07	Sound pressure level	104dB(2.0W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.4 KHz.
08	Frequency Range	Fo –5K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz,1.0 W.	

REV NO.

REVISION NOTE

APPROVAL

DATE

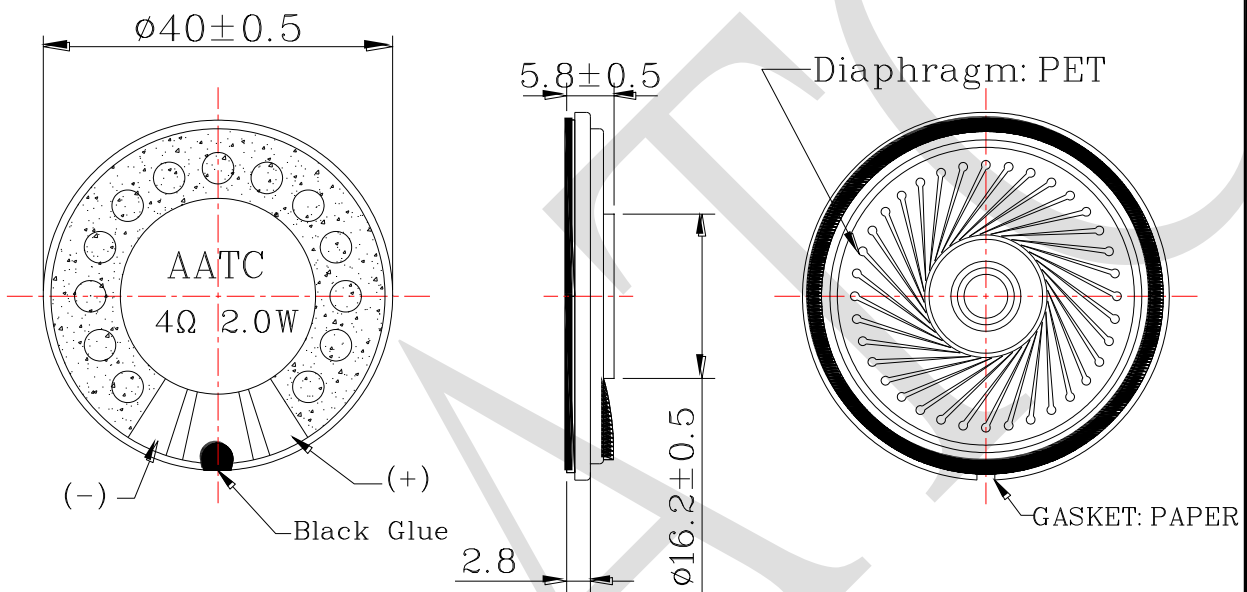

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Moose 2017/02/14

SCALE: 2:1

SHEET: 1:1

PART NO. AK-400420-MM-1

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL $\pm$ ***

DWG NO. CXS40058-R04W2.0-B

REV 1

MATERIAL: SPCC

TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-400420-MM-1](#)