


1. SPECIFICATION

AK-803108DC-1C8

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 80 X 31 mm	
03	Rated Input Power	2.5 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	8Ω ± 15% at 1.5KHz 1V	
06	Resonance Frequency (Fo)	630 Hz ± 20% at Fo, 1V	
07	Sensitivity (S.P.L.)	77 dB(1.0W/1.0M) ± 3 dB	at AVE 1.0, 1.2, 1.6, 2.0 KHz.
		101 dB(2.5W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 9 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

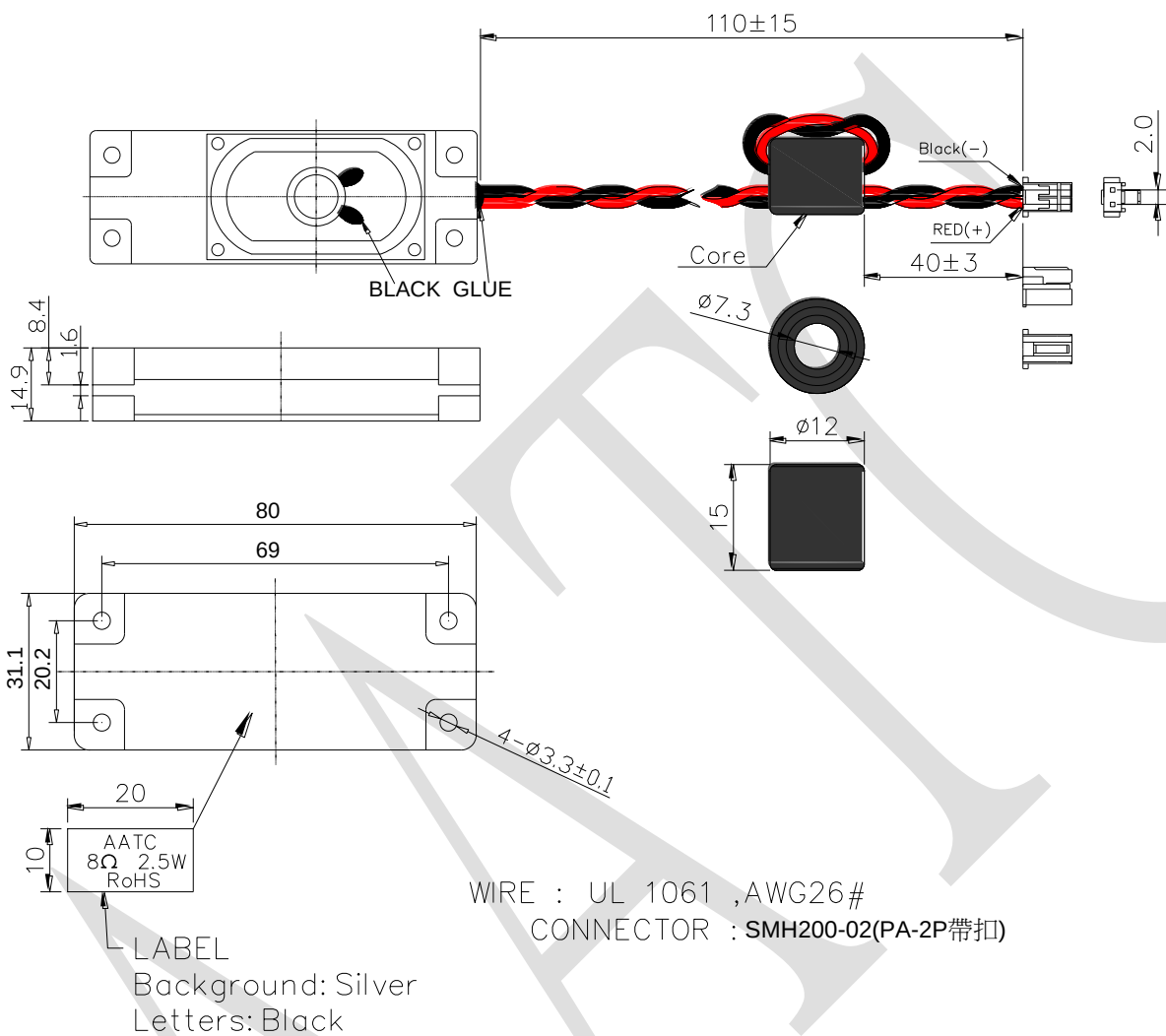

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2016/01/04	SCALE: 1:1	SHEET: 1 : 1
PART NO. AK-803108DC-1C8	3	DESIGNED: R & D OF AAT	UNITS: mm		
		CHECKED:	TOLERANCE ± 0.5		
DWG NO. YGDA8031YX-02C110-01	REV	APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: ABS	ONE PLACE DECIMAL ± ***		
		TWO PLACE DECIMAL ± ***			
		THREE PLACE DECIMAL ± ***			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-803108DC-1C8](#)