


File Name:

AZ-4229S-D

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	4~28	
03	Rated Current	mA(Max)	8	At 12 VDC
04	Sound Output At 60 cm	dBA(Min)	85	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Continuous		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	35	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

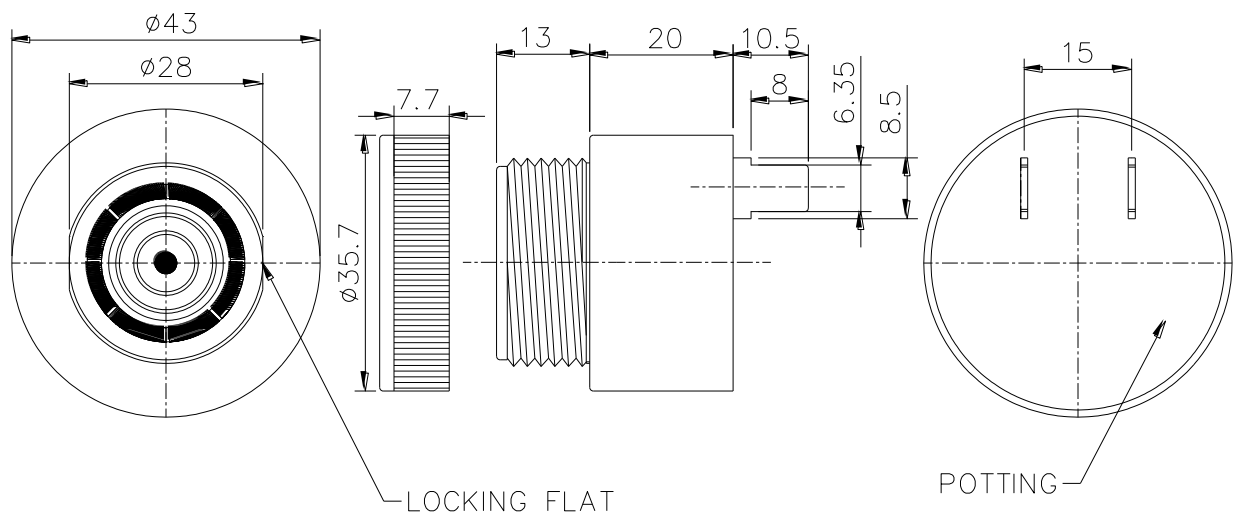

TITLE: <i>PIEZO BUZZER</i>		1 REV	DRAWN: JOAN 11/15/2001	SCALE: 1:1	SHEET: 1 of 1	
PART NO. <i>AZ-4229S-D</i>			DESIGNED: <i>R & D OF AAT</i>	UNITS: <i>mm</i>		
DWG NO. <i>DTP-1105</i>			CHECKED:	TOLERANCE ± 0.5 mm		
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
			MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL \pm ***		
				TWO PLACE DECIMAL \pm ***		
				THREE PLACE DECIMAL \pm ***		



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4229S-D](#)