


1. SPECIFICATION

AKV-24150808-PM-1W

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 24 x 15 mm	
03	Rated Input Power	0.8 W	
04	Max. Input Power	1.2 W for 1 minute	
05	Impedance	8Ω ± 15% at 1KHz 1V	
06	Resonance Frequency (Fo)	950 Hz ± 20% at Fo, 1V	
07	Sound pressure level	86 dB(0.1W/0.1M) ± 3 dB	at AVE 0.8K, 1.0K, 1.2K, 1.5 KHz.
		92 dB(0.8W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 6 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.8W(0.89V rms)	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

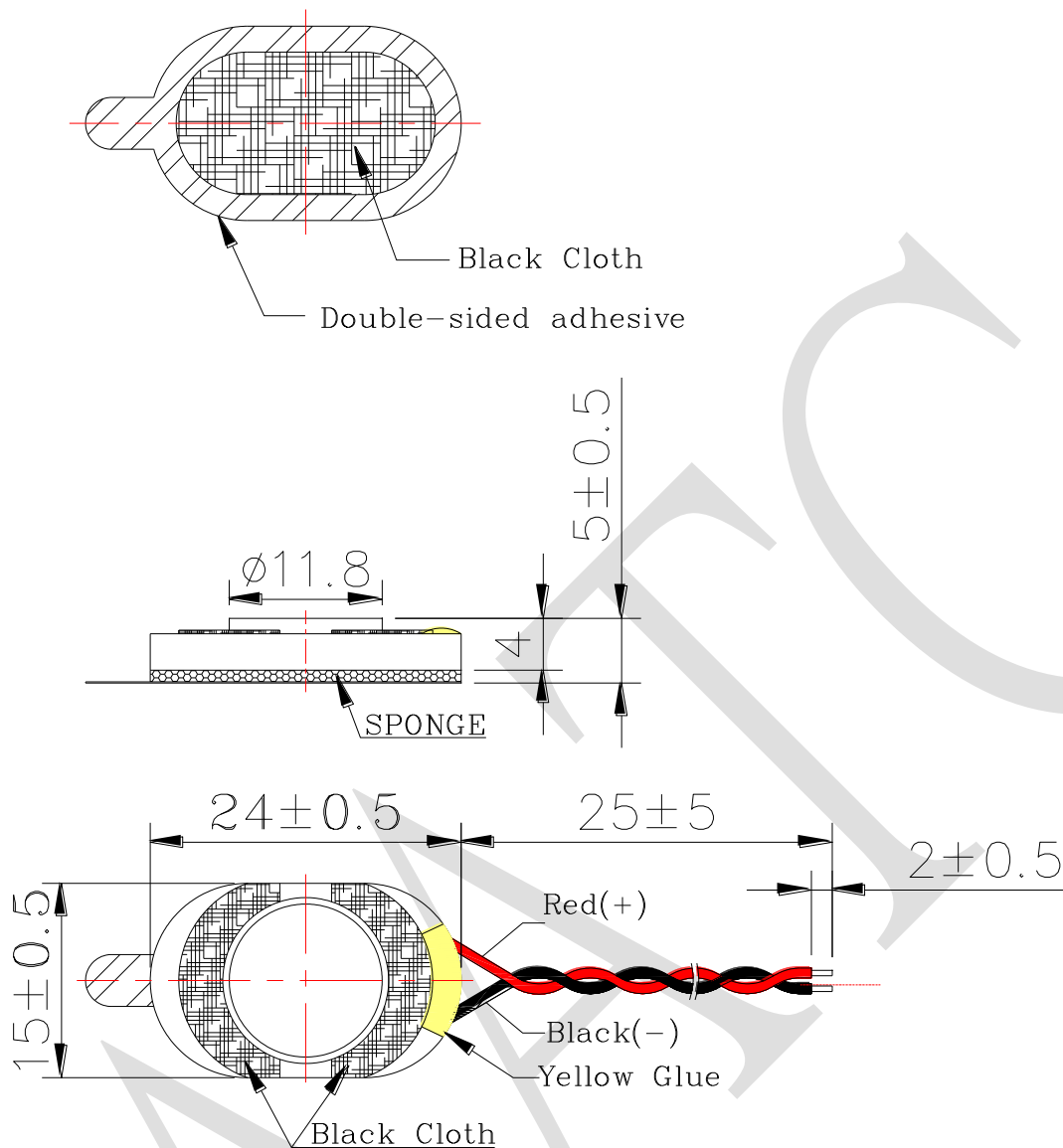

Wire: UL 3302,AWG30#

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2017/12/07	SCALE: 2:1	SHEET: 1:1
PART NO. AKV-24150808-PM-1W	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. CXS2415050L25-R08W0.8-A		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ABS		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKV-24150808-PM-1W](#)