

File Name:

AZ-4229S-FJ1


Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	6~28	
03	Rated Current	mA(Max)	9	At 12 VDC
04	Sound Output At 60 cm	dBA(Min)	95	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Fast Pulse		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	30	

REV NO.

REVISION NOTE

APPROVAL

DATE

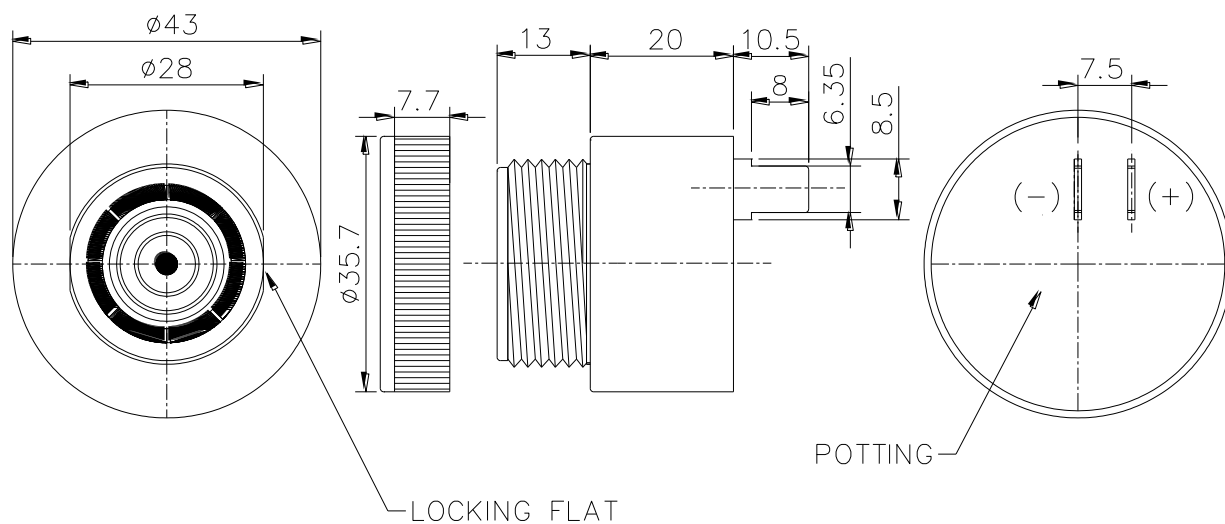

TITLE: PIEZO BUZZER

DRAWN: JOAN

07/03/2003

SCALE: 1:1 SHEET: 1 of 1

PART NO. AZ-4229S-FJ1

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO. DTP-1107

CHECKED:

TOLERANCE ± 0.5 mm

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***

REV

MATERIAL: *****

TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4229S-FJ1](#)