


1. SPECIFICATION

AE-2040E-WV-LF

TYPE		EXTERNAL -drive type sound element		
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Input Voltage	V (Max)	30	Vp-p (Square Wave) 1/2 duty
02	Resonant Frequency	KHz	4.0± 0.5	The resonant resistance is suitable only for piezo element without wire
03	Resonant Impedance	Ω (Max)	300	The resonant resistance is suitable only for piezo element without wire.
04	Capacitance	pF	20000±30%	At 1000Hz
05	Plate Material			BRASS

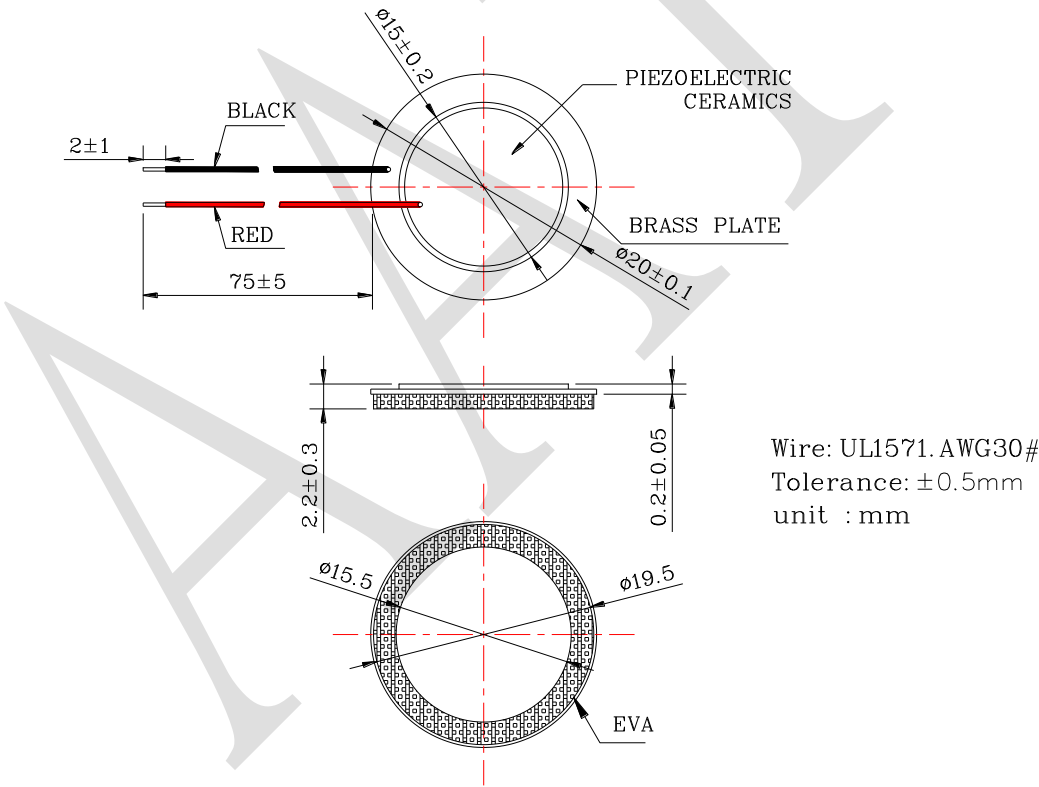

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AE-2040E-WV-LF](#)