

1. SPECIFICATION

AKB-803108C-2W


ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 80x31.1 mm	
03	Rated Input Power	2.5 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	8Ω ± 15% at 1.5KHz 1V	
06	Resonance Frequency (Fo)	630Hz ± 20% at Fo, 1V	
07	Sound pressure level	77 dB(1.0W/1.0M) ± 3 dB	at AVE 1.0, 1.2, 1.6, 2.0KHz.
		101 dB(2.5W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 9 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 2.83V.	

REV NO.

REVISION NOTE

APPROVAL

DATE

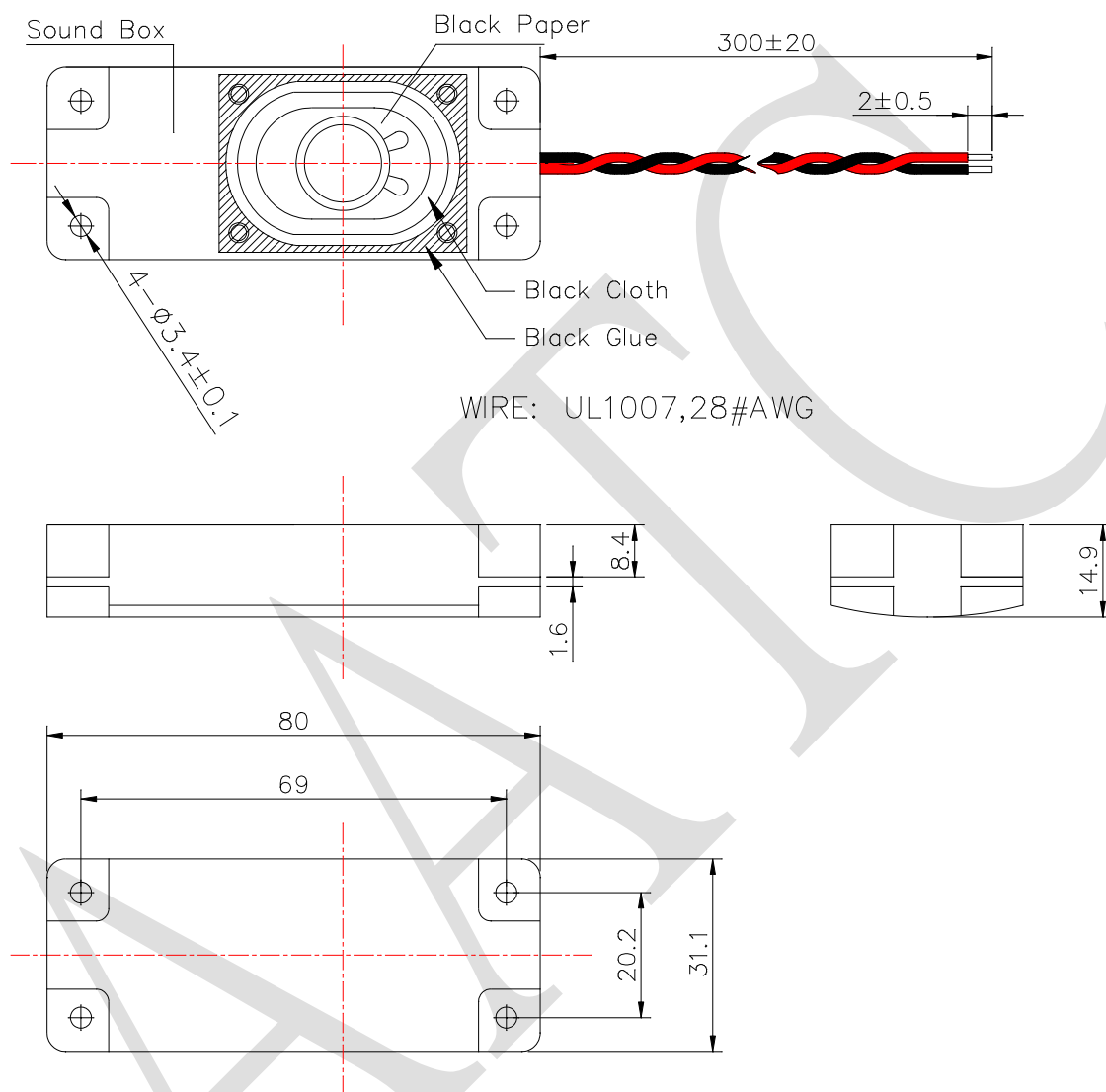

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Sunny

2015-5-25

SCALE: 1:1

SHEET: 1 : 1

PART NO. AKB-803108C-2W

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. CA-K15052501

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

REV

MATERIAL: ABS



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

AATC

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKB-803108C-2W](#)