

1. SPECIFICATION

AK-1275808WC-1


ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 127 x 58 mm	
03	Rated Input Power	10 W	
04	Max. Input Power	15 W for 1 minute	
05	Impedance	8Ω ± 15% at 0.8KHz 1V	
06	Resonance Frequency (Fo)	150 Hz ± 20% at Fo, 1V	
07	Sound pressure level	96 dB(1.0W/0.1M) ± 3 dB	at AVE 1.0, 1.2, 1.5, 1.8 KHz.
		92 dB(10W/0.5M) ± 3 dB	
08	Frequency Range	Fo – 18 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz 1.5V..	

REV NO.

REVISION NOTE

APPROVAL

DATE

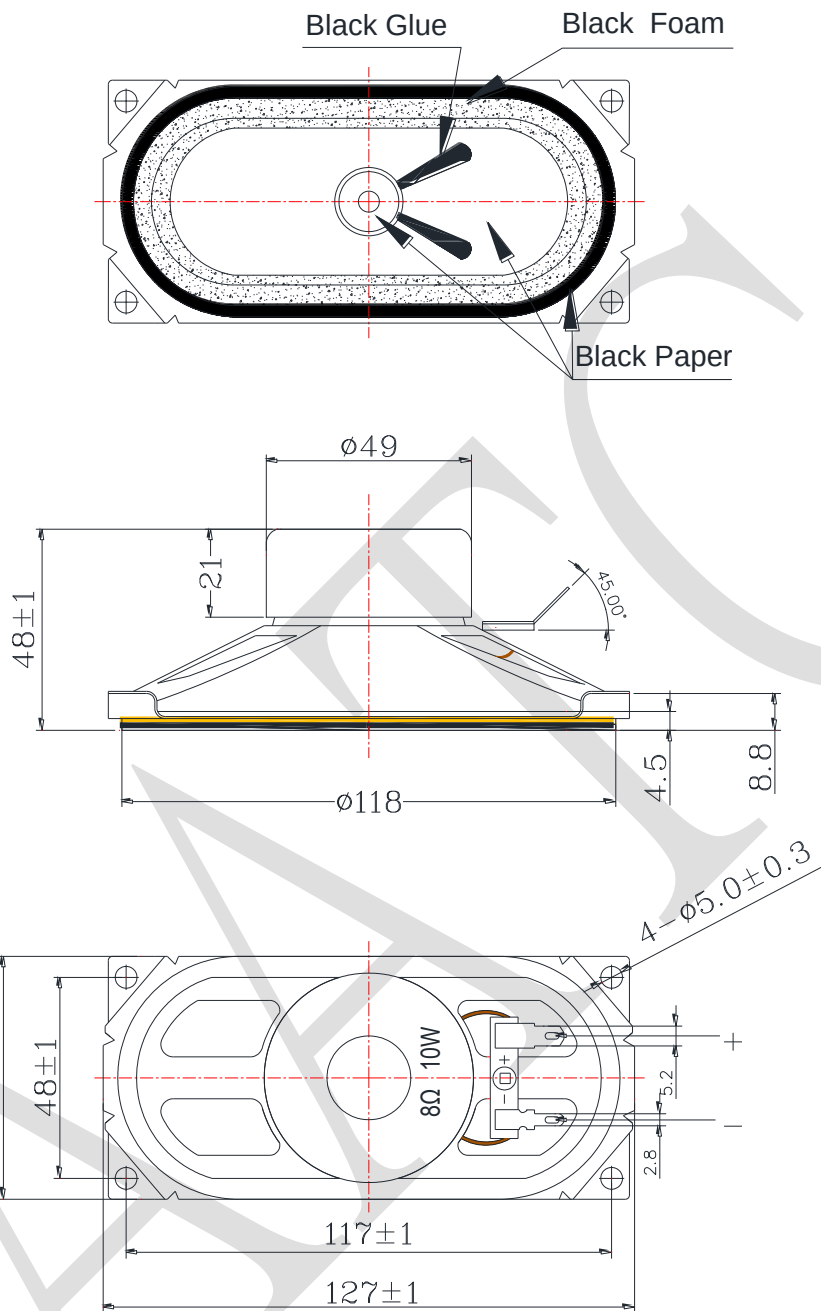

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Hank

2020/3/17

SCALE: 2:1

SHEET: 1:1

PART NO. AK-1275808WC-1

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. TV-58127FMA-R

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV

MATERIAL: IRON

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-1275808WC-1](#)