


1. SPECIFICATION

AR-28300-1C (RoHS)

ITEMS.		SPECIFICATIONS
01	Type	Dynamic 28 mm receiver unit
02	Sensitivity (S.P.L)	91dB $\pm$ 3 dB at 1kHz 60mV with IEC 318 coupler
03	Impedance.	300 Ohm $\pm$ 20% at 1KHz
04	Frequency Range	300 – 4000Hz
05	Nominal Input Power	50 mW
06	Max. Input Power.	100 mW for 1 minute.
07	Total Harmonics Distortion	Max 5 % at 1K Hz.

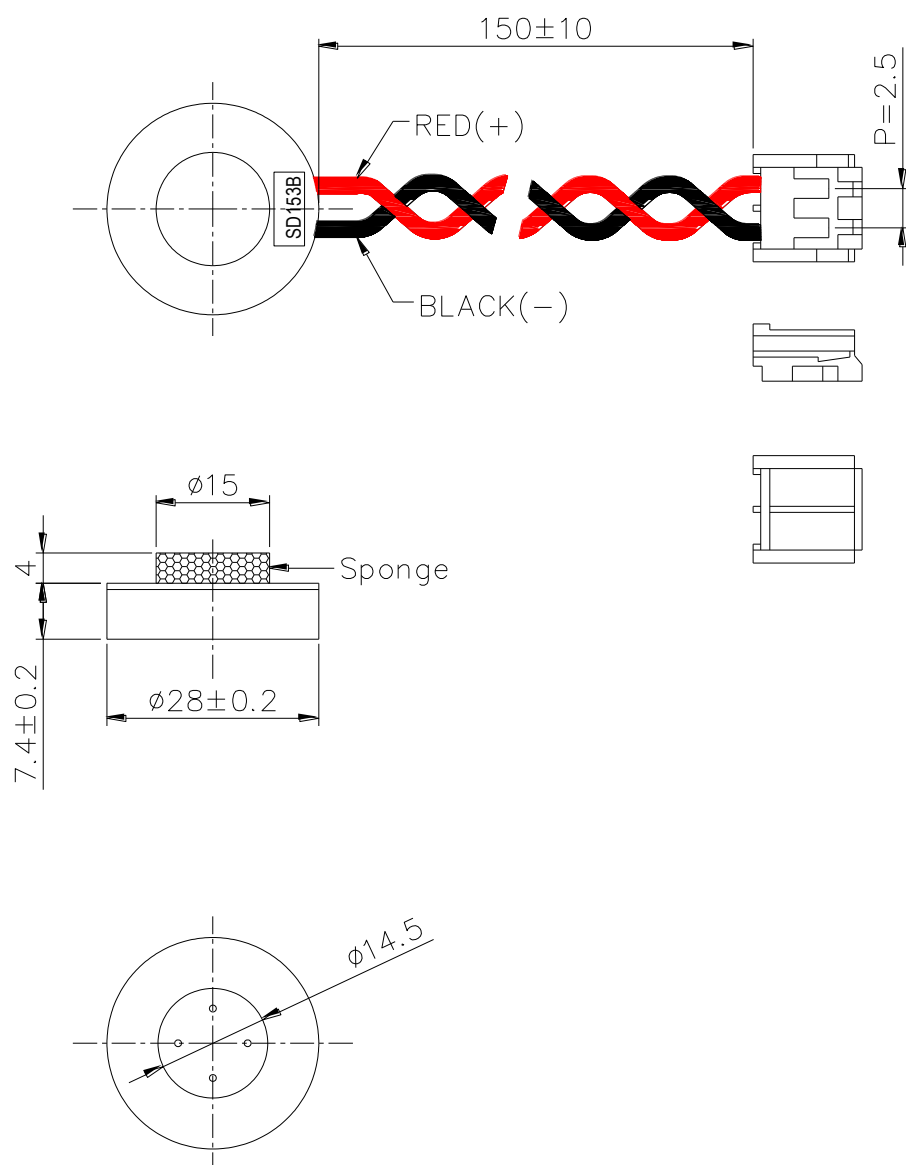

WIRE : UL 1571 , AWG28 .

CONNECTOR:A2502TOP-2.0

DIAPHRAGM:PET

TITLE: TELEPHONE RECEIVER

DRAWN: Lemon 2009-12-24

SCALE: 1:1 SHEET: 1:1

PART NO. AR-28300-1C

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. HS-R09122402

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

MATERIAL: ABS



笠翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AR-28300-1C](#)