


1. SPECIFICATION

AK-150805-PM-6

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 15 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	0.8 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 1KHz 1V	
06	Resonance Frequency (Fo)	1000 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	$91 \text{ dB}(0.5\text{W}/0.1\text{M}) \pm 3 \text{ dB}$	at AVE 1.2,1.4, 1.6, 1.8 KHz.
08	Frequency Range	Fo – 9.0 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

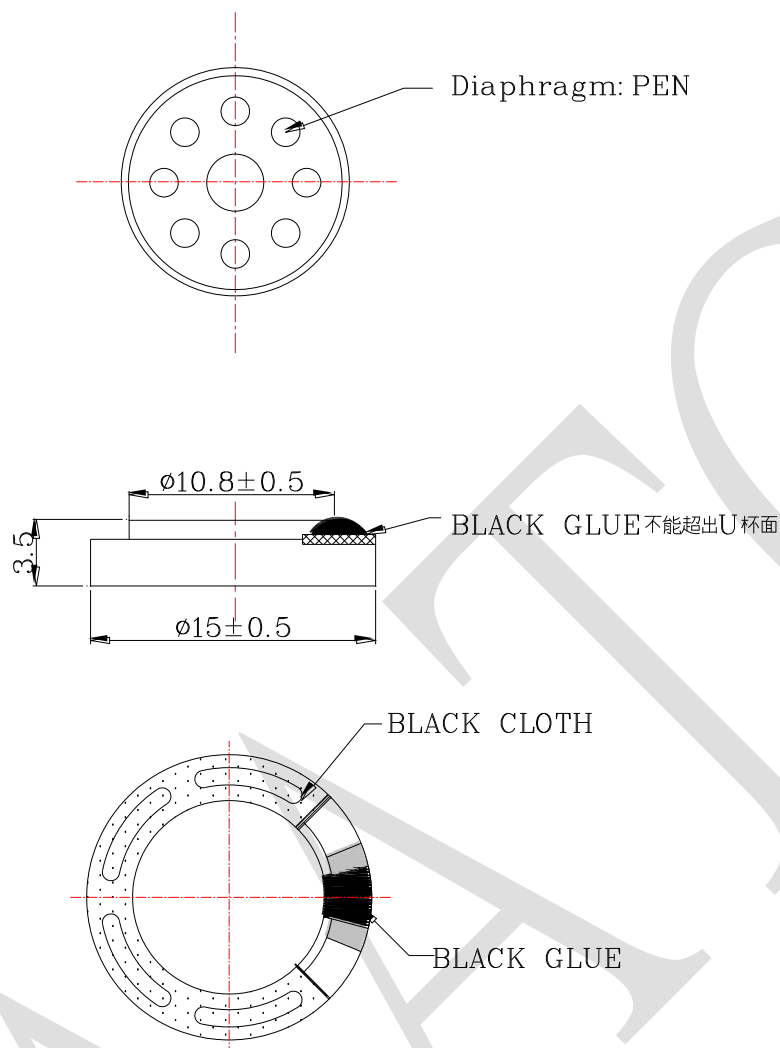

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Moose	2018-06-21	SCALE: 2:1	SHEET: 1:1
PART NO.	1	DESIGNED: R&D OF AAT	UNITS: mm		
AK-150805-PM-6		CHECKED:	TOLERANCE ± 0.5		
DWG NO. JXS15-08-02		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: SPCC/PBT	ONE PLACE DECIMAL ± ***		
			TWO PLACE DECIMAL ± ***		
			THREE PLACE DECIMAL ± ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-150805-PM-6](#)