

1. SPECIFICATION

AKR-15110806-PAM-1PV

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 15 x 11 mm	
03	Rated Input Power	0.6 W	
04	Max. Input Power	1.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 2.0KHz 1V	
06	Resonance Frequency (Fo)	650 Hz $\pm$ 20% at Fo, 1V	
07	Sound pressure level	85 dB(0.6W/0.1M) $\pm$ 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
08	Frequency Range	Fo – 10 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.89V.	


REV NO.

REVISION NOTE

APPROVAL

DATE

Recommended PAD LAYOUT

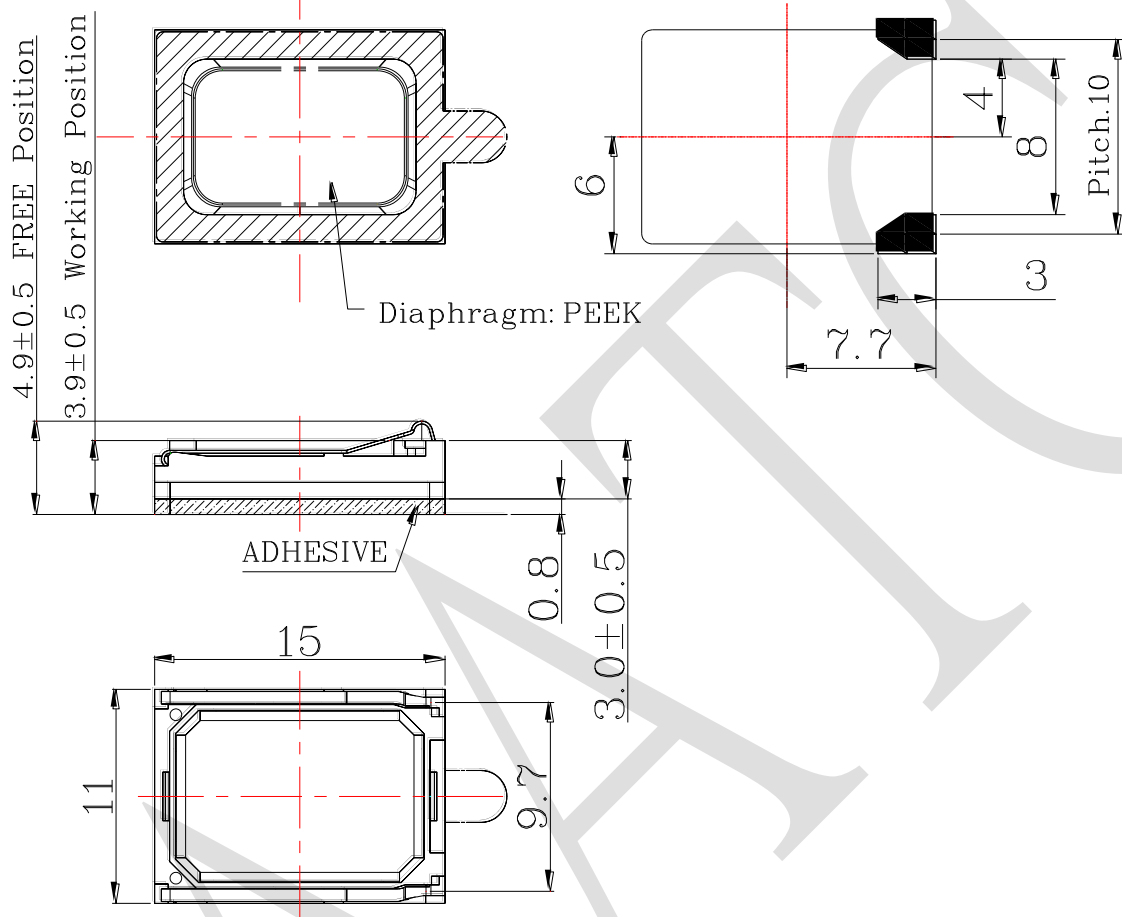

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Moose

2016-04-12

SCALE: 1:1

SHEET: 1 : 1

PART NO.

AKR-15110806-PAM-1PV

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. *****

1

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

REV

MATERIAL: PBT



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKR-15110806-PAM-1PV](#)