

1. SPECIFICATION

AKB-2308D-P


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 22.6 mm	
03	Rated Input Power	0.1 W	
04	Max. Input Power	0.2 W for 1 minute	
05	Impedance	8Ω ± 15% at 1KHz 1V	
06	Resonance Frequency (Fo)	1600 Hz ± 20% at Fo, 1V	
07	Sound pressure level	87dB(0.2W/0.1M) ± 3 dB	at AVE 2.0,2.2, 2.5, 2.8 KHz.
		84 dB(0.1W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 4 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.89V.	

REV NO.

REVISION NOTE

APPROVAL

DATE

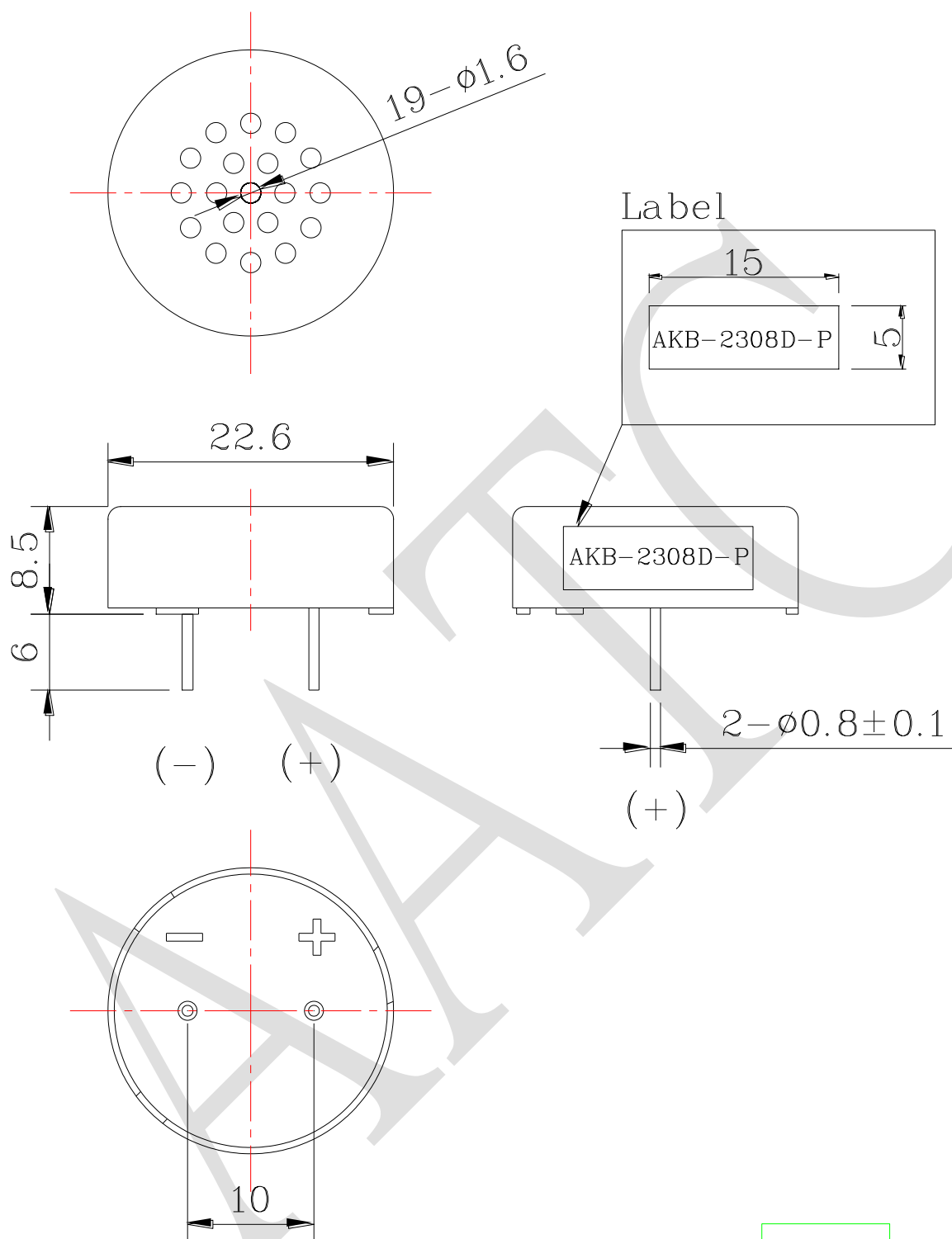

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Jerry	2013/07/22	SCALE: 2:1	SHEET: 1:1
PART NO. AKB-2308D-P	1	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. BD23A-801		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: NORYL	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AKB-2308D-P](#)