

1. SPECIFICATION

AK-150805-PM-2WV


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 15 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	1.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$	
06	Resonance Frequency (Fo)	1350Hz $\pm$ 20% at Fo, 1V	
07	Sound pressure level	96dB (0.5W/0.1M) $\pm$ 3 dB	at AVE 1.2, 1.3, 1.4,1.5 KHz.
08	Frequency Range	Fo –20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W.	

REV NO.

REVISION NOTE

APPROVAL

DATE

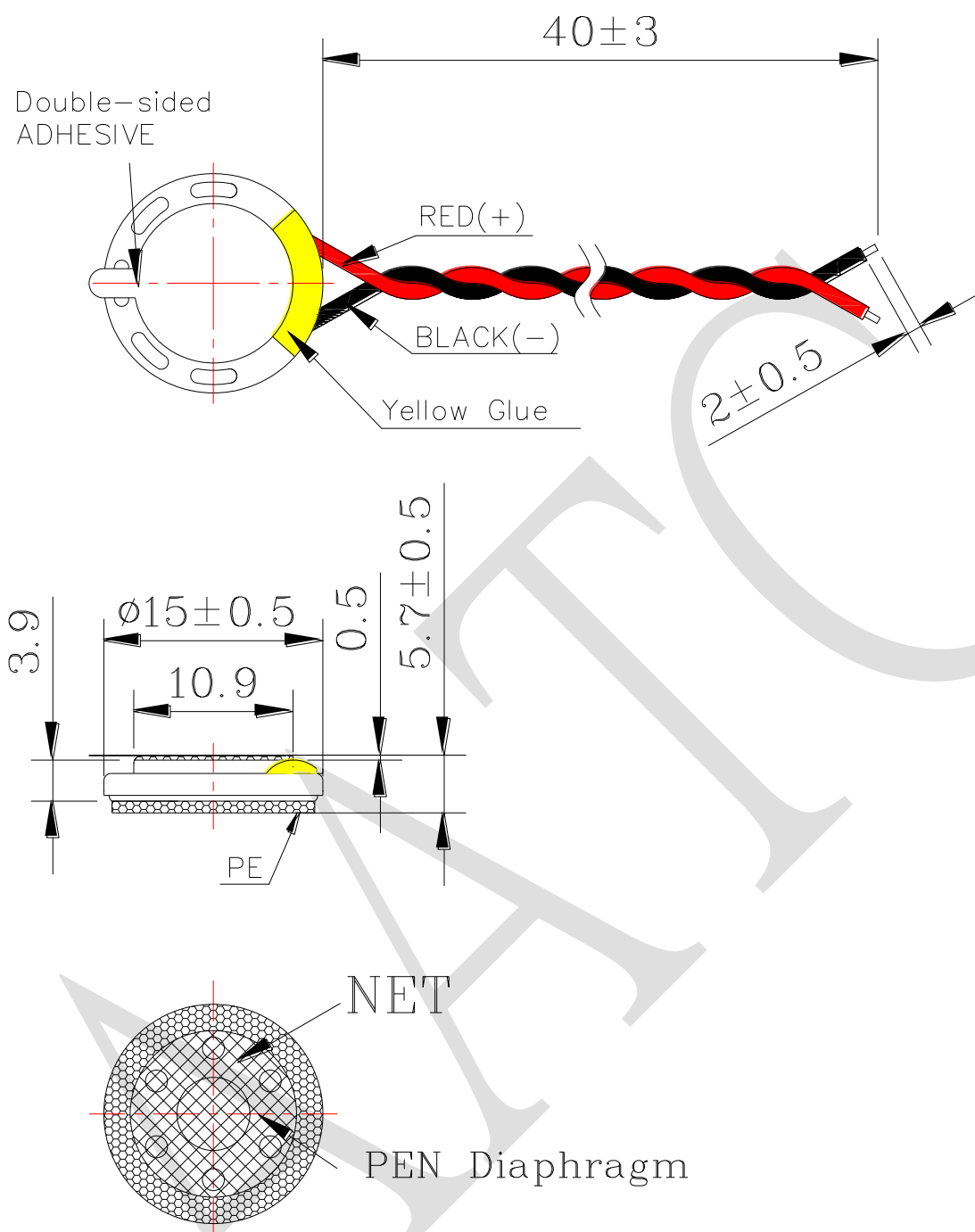

WIRE: UL1571,AWG32#

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Zack

2016/06/14

SCALE: 2:1

SHEET: 1:1

PART NO. AK-150805-PM-2WV

1

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

DWG NO. JXS15-08-03W40D1.1-S0.5

REV

MATERIAL: PBT



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-150805-PM-2WV](#)