


1. SPECIFICATION

AKR-P1511M8-1WV

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 15 x 11 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	0.8 W for 1 minute	
05	Impedance	8Ω ± 15% at 2KHz 1V	
06	Resonance Frequency (Fo)	650 Hz ± 20% at Fo, 1V	
07	Sound pressure level	75 dB(0.1W/0.1M) ± 3 dB	at AVE 0.6K, 0.8K, 1.0K, 1.2K KHz.
		81 dB(0.5W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 5 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

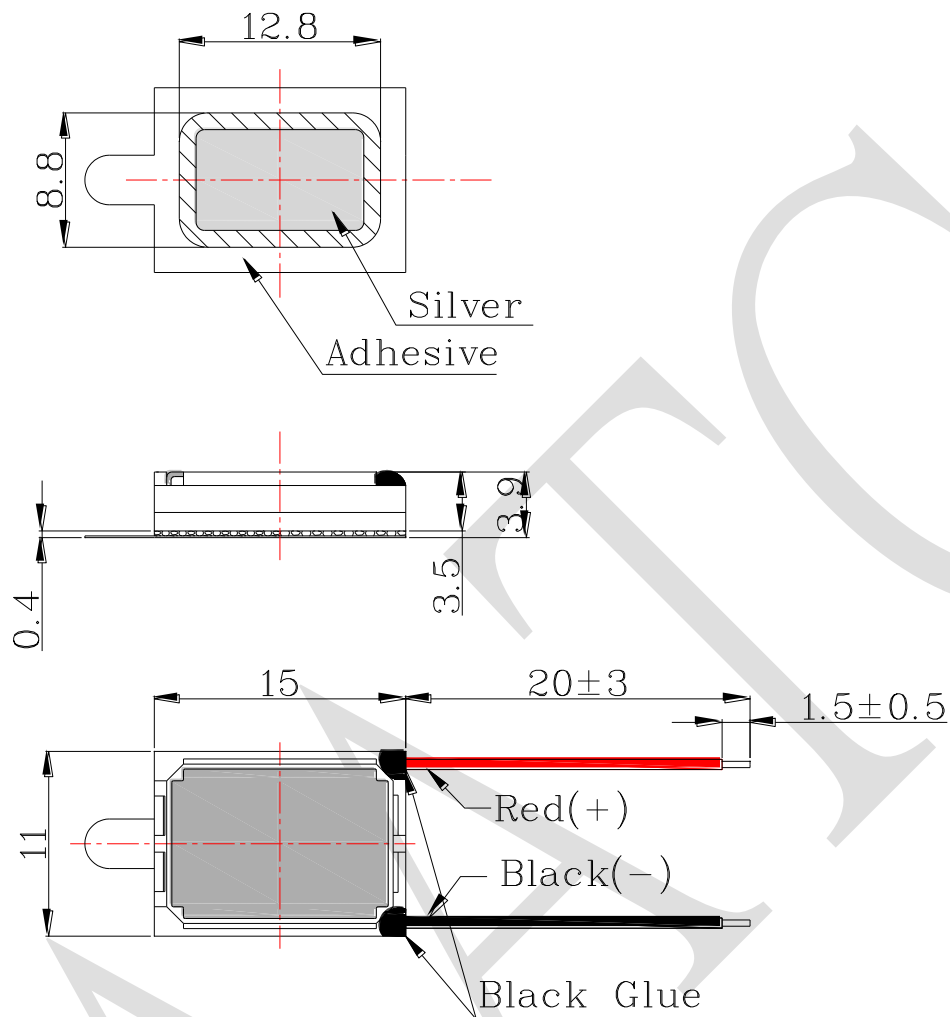

Wire: UL1571.AWG32#

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2015/08/04	SCALE: 1:1	SHEET: 1 : 1
PART NO. AKR-P1511M8-1WV	2	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. JXS1511-08-07W20		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: PBT		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKR-P1511M8-1WV](#)