

File Name:

1. SPECIFICATION

AR-1032IA-4W (RoHS)




ITEMS.		SPECIFICATIONS
01	Type	Dynamic 10 mm receiver unit
02	Sensitivity (S.P.L)	104dB $\pm$ 3 dB at 1kHz 100 mV with IEC 318 coupler
03	Impedance.	32 Ohm $\pm$ 15% at 1KHz
04	Frequency Range	300 – 3.4K Hz
05	Nominal Input Power	10 mW
06	Max. Input Power.	20 mW for 1 minute.
07	Total Harmonics Distortion	Max 5 % at 1K Hz,1 mW .

REV NO.

REVISION NOTE

APPROVAL

DATE

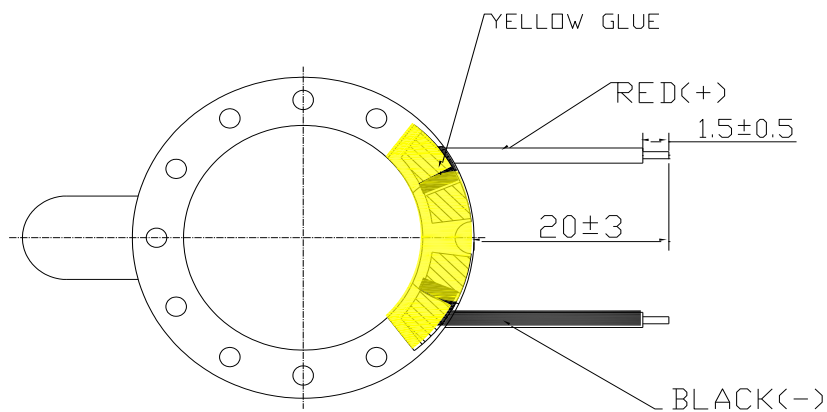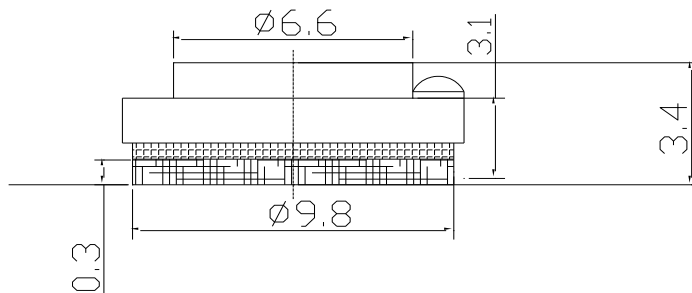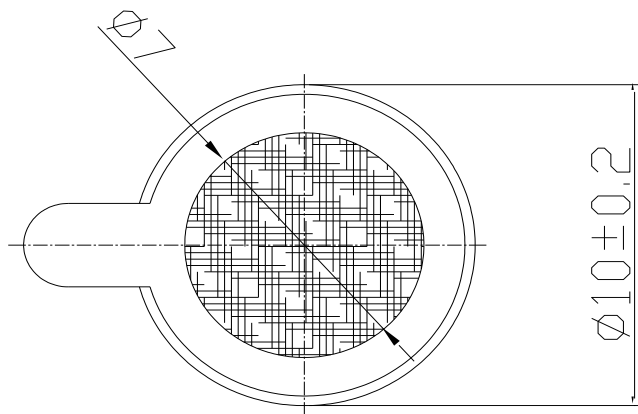

WIRE:UL1571 32 AWG

TITLE: DYNAMIC RECEIVER

DRAWN: TOM 2008/07/30

SCALE: 1:1 SHEET: 1 : 1

PART NO. AR-1032IA-4W

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. EAD-145

APPROVAL:

UNLESS OTHERWISE SPECIFIED:
ONE PLACE DECIMAL $\pm$ ***

REV

MATERIAL: ****

TWO PLACE DECIMAL $\pm$ ***
THREE PLACE DECIMAL $\pm$ ***

苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AR-1032IA-4W