
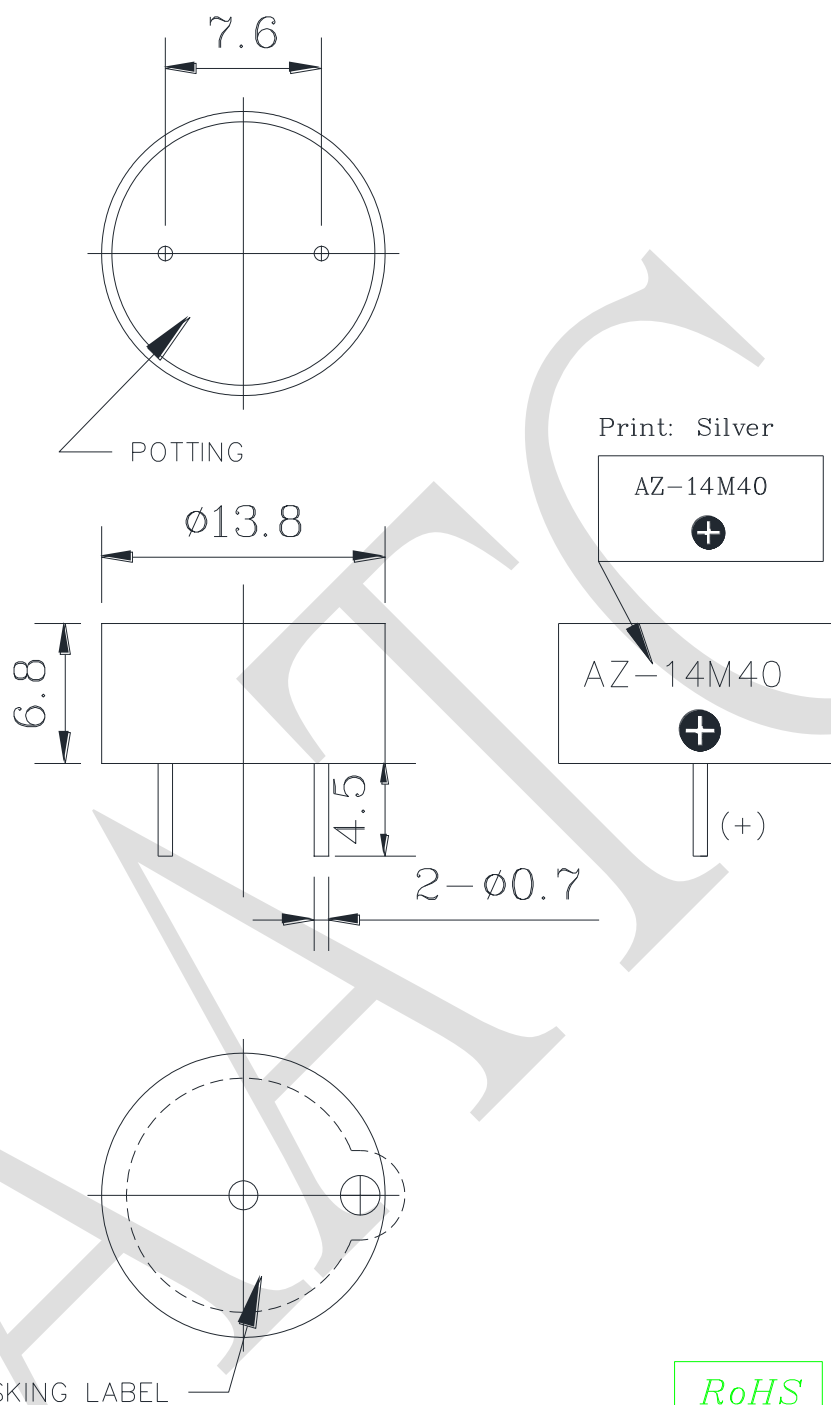


1. SPECIFICATION

AZ-14M40

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	 <p>Square wave 1/2 duty.</p>
02	Operating Voltage	V	1 ~ 30	
03	Consumption Current	mA (Max)	5	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	80	Rated voltage, rated frequency.
05	Capacitance	pF	13000±30%	At 120Hz
06	Rated Frequency	Hz	4000	
07	Operating Temp.	℃	-40 ~ +85	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	1	
10	Housing Material		NORYL	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Hank	2020/01/20	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-14M40</i>	1	DESIGNED: <i>R&D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>DTP-1008</i>		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>NORYL</i>		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1440E-P-LF](#) [AZ-14M40](#)