

1. SPECIFICATION

AS-501A-LF




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA Max.	35	Standard state, standard drive circuit. Square wave 1/2 duty.
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	78	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	16±2.4	
06	Rated Frequency	Hz	2048	
07	Operating Temp.	℃	-30 ~ +70	
08	Storage Temp.	℃	-40 ~ +80	
09	Weight	g	1.5	

REV NO.

REVISION NOTE

APPROVAL

DATE

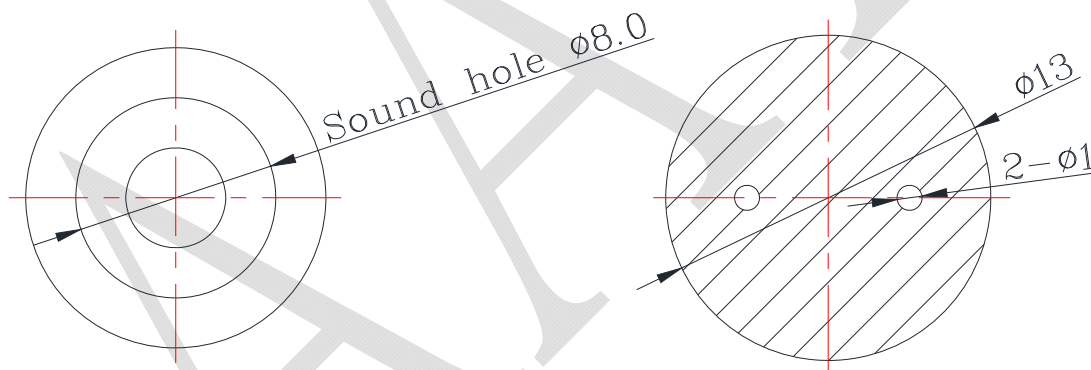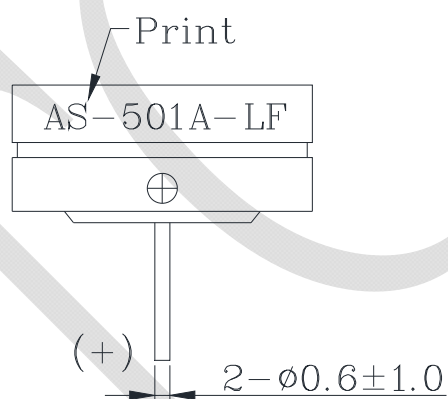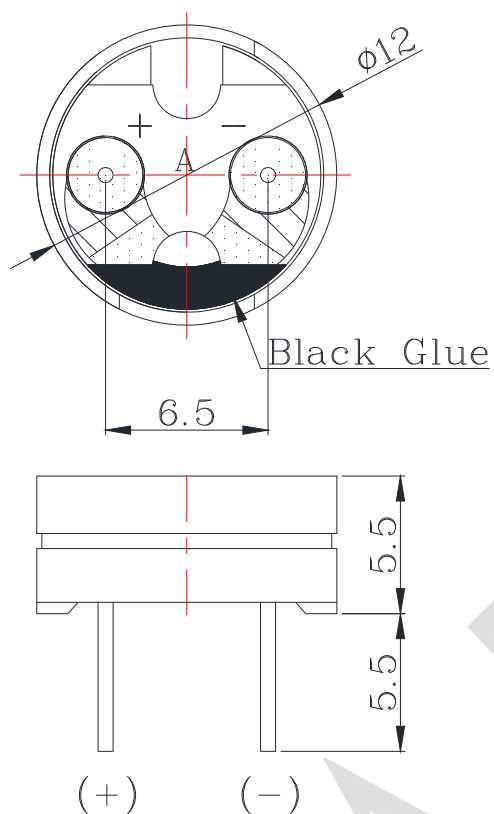

RECOMMENDED PCB LAYOUT

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: *Zack* 2020/06/09

SCALE: 4:1 SHEET: 1 of 1

PART NO. AS-501A-LF

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGC12G-105AP5.5A

3

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: NORYL

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AS-501A-LF](#)