


1. SPECIFICATION

AZ-1720E-P-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 25	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	70	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	2000± 300	Rated Voltage
06	Capacitance	pF	34000±30%	At 120Hz
07	Operating Temp.	℃	-20 ~ +70	
08	Storage Temp.	℃	-40 ~ +80	
09	Weight	g	1.4	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

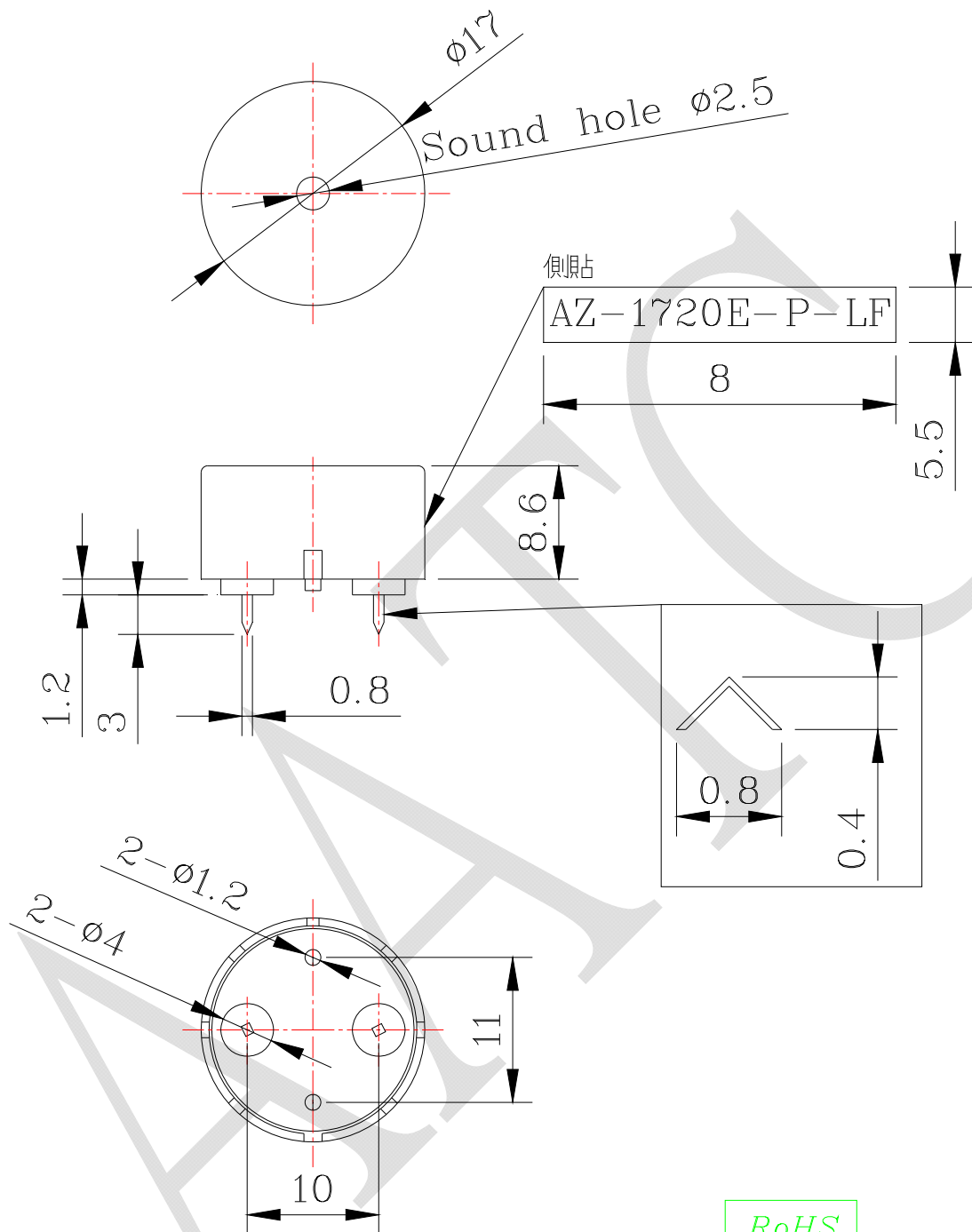

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Jack</i> 2015/01/28	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1720E-P-LF</i>		DESIGNED: R&D OF AAT	UNITS: mm	
DWG NO. <i>UGPA17E2003P</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>NORYL</i>	ONE PLACE DECIMAL \pm ***	
REV 4			TWO PLACE DECIMAL \pm ***	
			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1720E-P-LF](#)