
 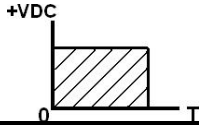



1. SPECIFICATION

AI-1203B-1P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	2300± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage / Resonant Frequency
07	Operating Temp.	℃	-30 ~ +70	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	PBT	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

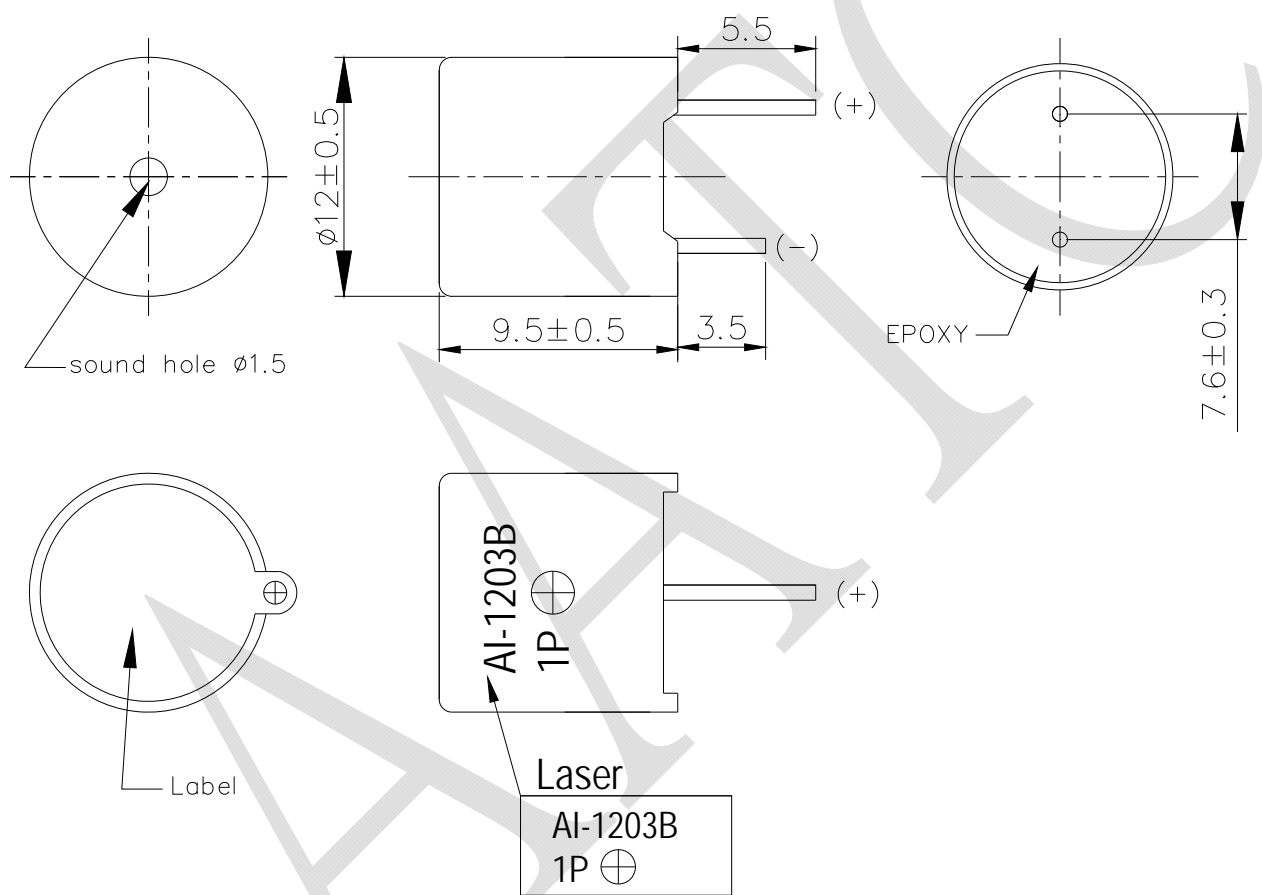

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: <i>Jack</i> 2017/11/20	SCALE: 4:1	SHEET: 1 of 1
PART NO. AI-1203B-1P	1 REV	DESIGNED: R&D OF AAT	UNITS: mm	
DWG NO. UGCM1203XP5.5/3.5IC		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL \pm *** TWO PLACE DECIMAL \pm *** THREE PLACE DECIMAL \pm ***	
		MATERIAL: PBT		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AI-1203B-1P](#)