


1. SPECIFICATION

AE-2036E-N

TYPE		EXTERNAL -drive type sound element		
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Input Voltage	V (Max)	30	Vp-p (Square Wave) 1/2 duty
02	Resonant Frequency	KHz	3.6± 0.5	at 25± 2℃, 45~60% RH
03	Resonant Impedance	Ω (Max)	300	at 25± 2℃, 45~60% RH
04	Capacitance	pF	20000±30%	At 120Hz
05	Plate Material	BRASS		
06	Operating Temp.	℃	-20 ~ +60	
07	Storage Temp.	℃	-20 ~ +70	
08	Weight	g	0.5	

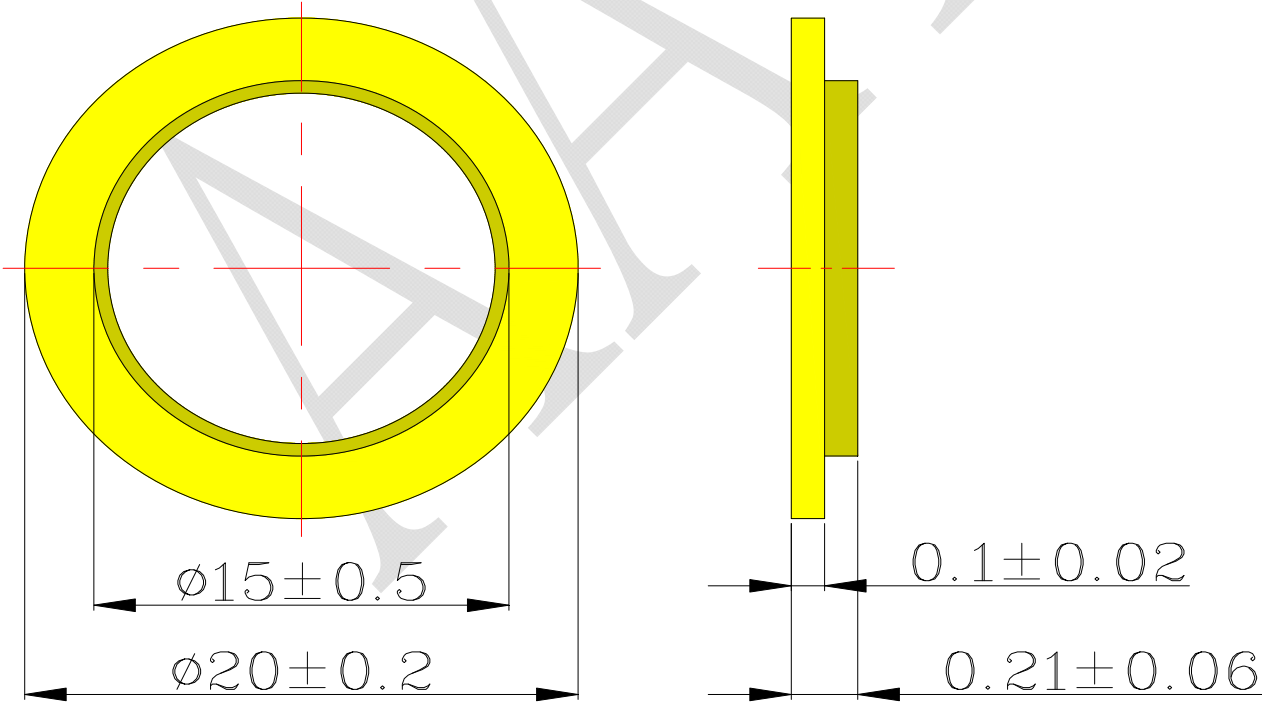

UNIT: mm
Toleranced: ±0.5mm

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AE-2036E-N](#) [AZ-2220E-P](#)