
 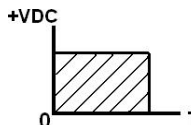

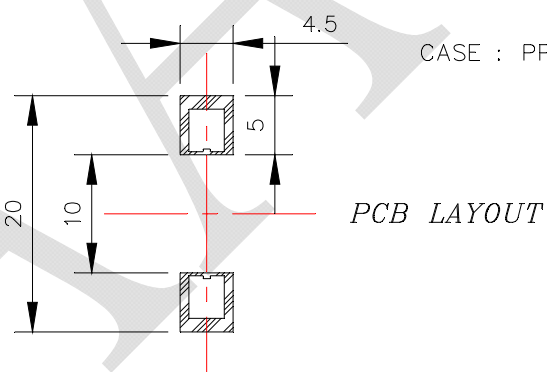
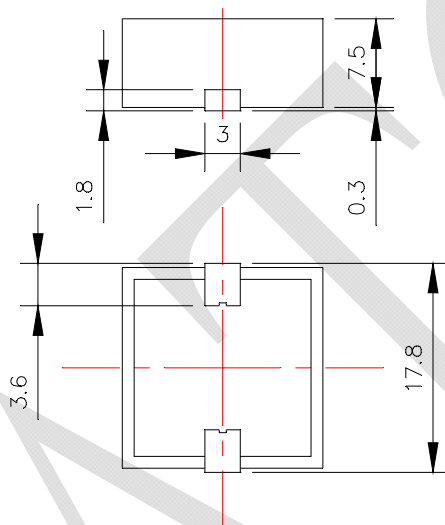


1. SPECIFICATION

APD-1712S-1-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	6 ~ 18	
03	Consumption Current	mA (Max)	8	Rated Voltage
04	Resonant Frequency	Hz	4000± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	83	Distance at 10cm Rated Voltage / Resonant Frequency
07	Operating Temp.	℃	-30 ~ +70	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	2.6	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

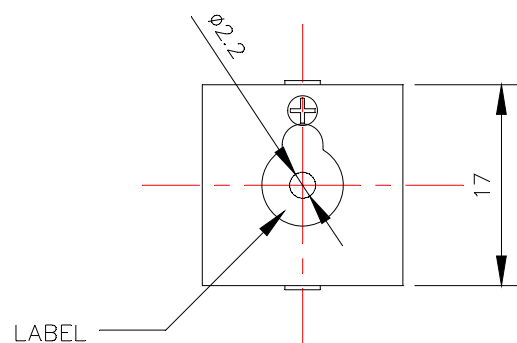

RoHS

TITLE: <i>PIEZO BUZZER SELF (SMD)</i>		DRAWN: Sunny	2018-7-3	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>APD-1712S-1-LF</i>		2	DESIGNED: R&D OF AAT		UNITS: mm
			CHECKED:		TOLERANCE ± 0.3
DWG NO. <i>DTS-1408</i>		REV	APPROVAL:		UNLESS OTHERWISE SPECIFIED:
			MATERIAL: PPS		ONE PLACE DECIMAL $\pm$ *** TWO PLACE DECIMAL $\pm$ *** THREE PLACE DECIMAL $\pm$ ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[APD-1712S-1-LF](#)