


1. SPECIFICATION

AZ-1348E-W-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 30	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm )	dBA(Min)	80	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4800± 300	Rated Voltage
06	Capacitance	pF	15000±30%	At 120Hz
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	1.0	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

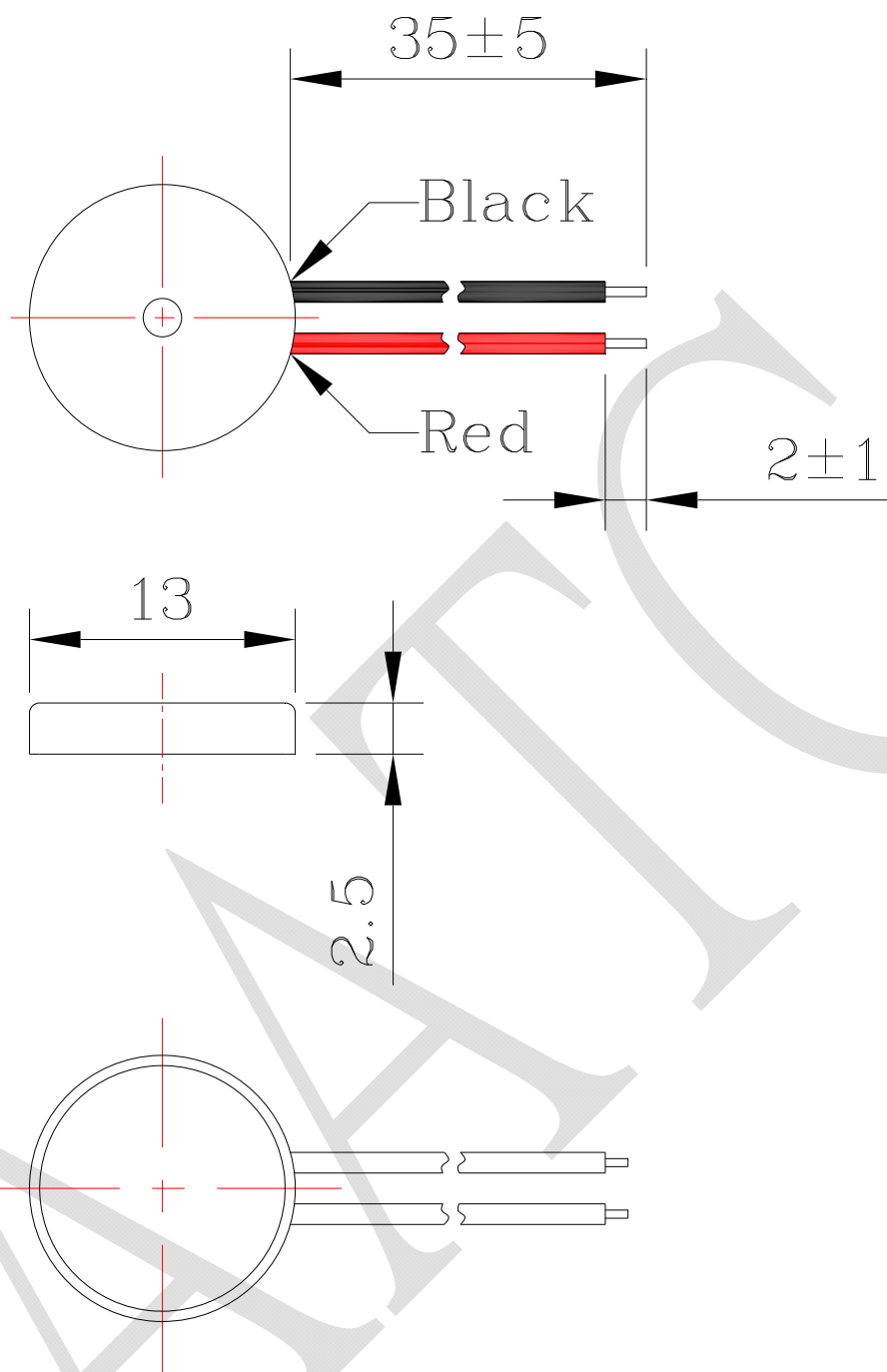

Wire: UL1571. AWG30#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Jerry</i> 2013/03/27	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1348E-W</i>	3	DESIGNED: R&D OF AAT	UNITS: mm	
		CHECKED:	TOLERANCE $\pm 0.5$	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
DWG NO. <i>UGPA13E4810W35</i>	REV	MATERIAL: ABS	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-1348E-W-LF