


1. SPECIFICATION

AE-2040E-N

TYPE		EXTERNAL -drive type sound element		
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Input Voltage	V (Max)	30	Vp-p (Square Wave) 1/2 duty
02	Resonant Frequency	KHz	4 ± 0.5	at $25 \pm 2^{\circ}\text{C}$, 45~60% RH
03	Resonant Impedance	Ω (Max)	300	at $25 \pm 2^{\circ}\text{C}$, 45~60% RH
04	Capacitance	pF	$26000 \pm 30\%$	At 100 Hz
05	Plate Material			BRASS
06	Operating Temp.	$^{\circ}\text{C}$	-20 ~ +60	
07	Storage Temp.	$^{\circ}\text{C}$	-20 ~ +70	
08	Weight	g	0.4	

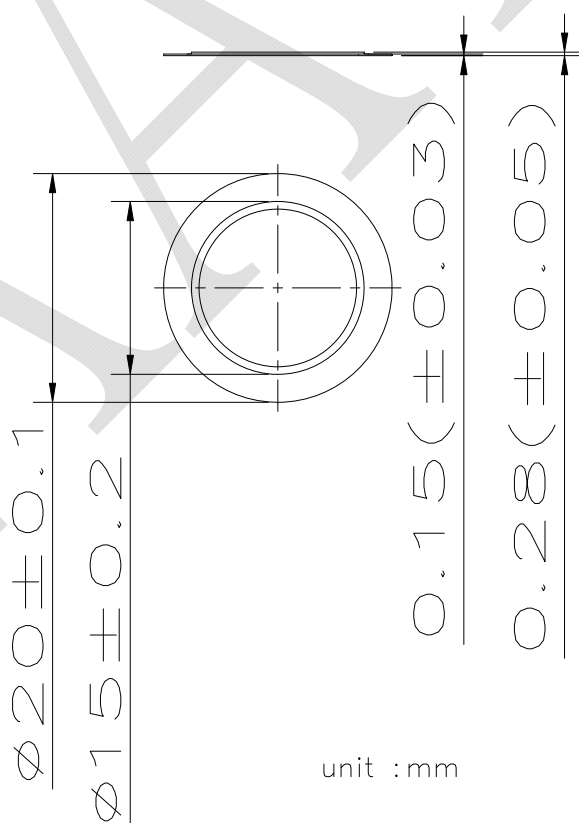

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AE-2040E-N](#)