


1. SPECIFICATION

AE-3529F-N

ITEM		CONDITION
01	Type.	EXTERNAL -drive type sound element
02	Input Voltage	30Vp-p Max
03	Resonant Frequency (KHz)	2.9± 0.5 at 25± 2℃ , 45~60% RH
04	Resonant Impedance (OHM)	200 OHM Max. at 25± 2℃ , 45~60% RH
05	Capacity (PF)	28000±30% at 1.0KHz 1Vrms
06	Plate Material	BRASS
07	Operating Temperature (℃)	-20 to +60
08	Storage Temperature (℃)	-20 to +70

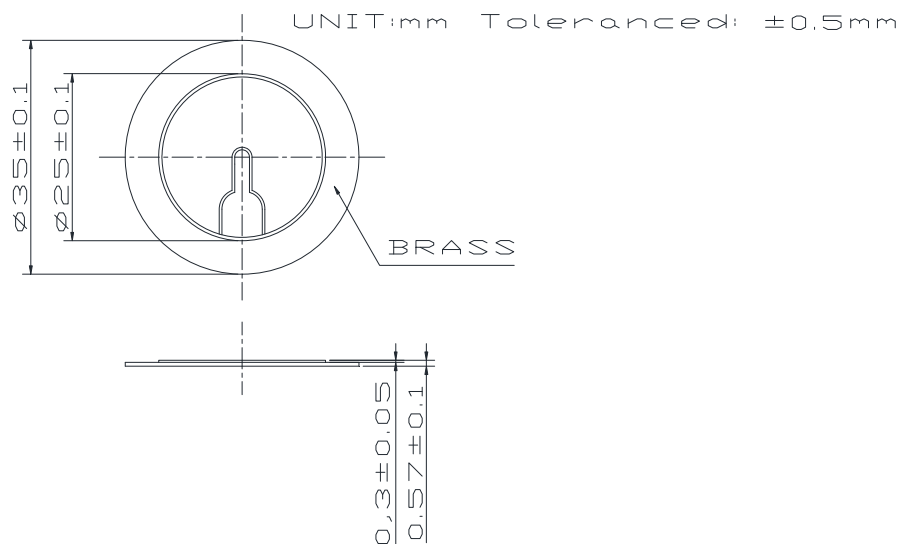

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AE-3529F-N](#)