



Items		Units	Specifications	Conditions
01	Rated Voltage	Vp-p	3	
02	Operating Voltage	Vp-p	1-30	
03	Rated Current (Max)	mA	3	
04	Min Sound Output	dBA	75	at 10cm
05	Resonant Frequency	Hz	4000±500	
06	Capacitance at 120Hz	pF	10000±30%	
07	Lead Pin Material	Beryllium Bronze		
08	Operating Temp.	℃	-20 ~ +70	
09	Storage Temp.	℃	-30 ~ +70	
10	Weight	g	3	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

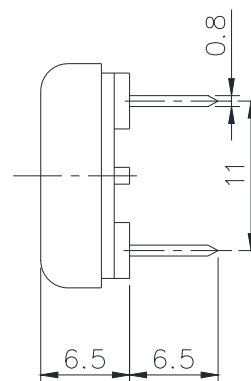

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Milton</i> 04/20/2001	SCALE: 2:1	SHEET: 1 : 1
PART NO. <i>AZ-1740E-P-LF</i>	1	DESIGNED: <i>R & D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>DTP-1012</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>NORYL</i>	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	

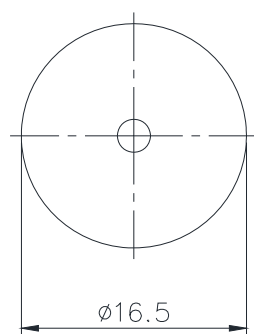

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1740E-P-LF](#)