

1. SPECIFICATION

AZ-2437S-P-LF





ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3~ 16	
03	Rated Current	mA(Max)	8	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3700	Rated Voltage
06	Resonant Frequency	Hz	3700± 500	
07	Tone Nature	Single		
08	Operating Temp.	℃	-20 ~ +70	
09	Storage Temp.	℃	-40 ~ +80	
10	Weight	g	5.2	

REV NO.

REVISION NOTE

APPROVAL

DATE

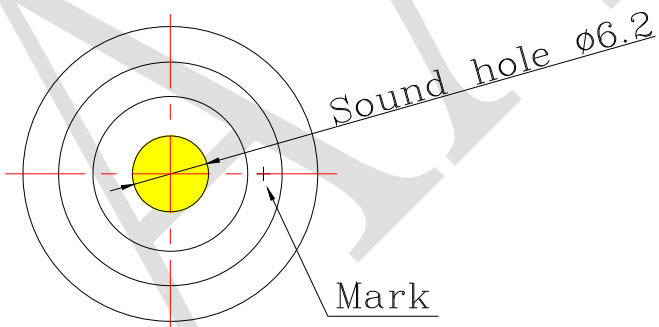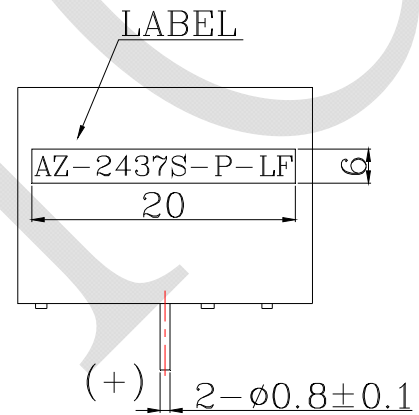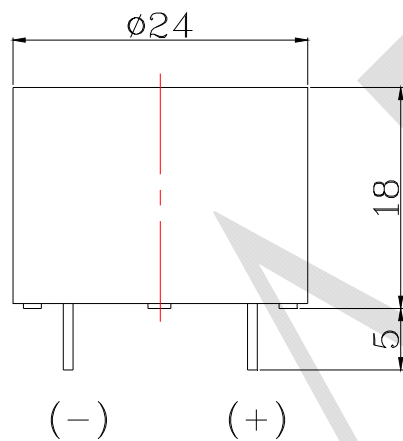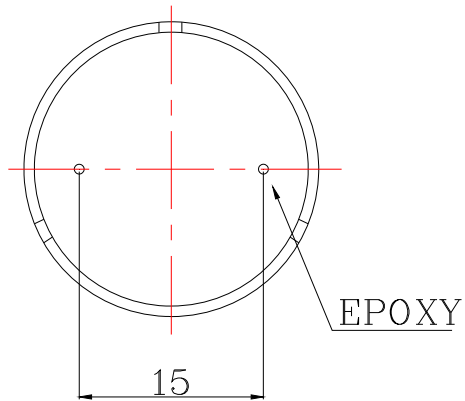

RoHS

TITLE: PIEZO BUZZER

DRAWN: Jerry 2014/03/20

SCALE: 2:1 SHEET: 1 of 1

PART NO. AZ-2437S-P-LF

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. UGPM24BX3712P

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2437S-P-LF](#)