


1. SPECIFICATION

AZ-2430E-A

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	3 ~ 28	
03	Rated Current	mA(Max)	10	At 12 VDC / 3.0KHz
04	Sound Output At 30 cm	dBA(Min)	80	At 12 VDC / 3.0KHz
05	Resonant Frequency	Hz	3000 ±500	
06	Operating Temp.	℃	-30 ~ + 80	
07	Storage Temp.	℃	-40 ~ +85	
08	Weight	g	3.4	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

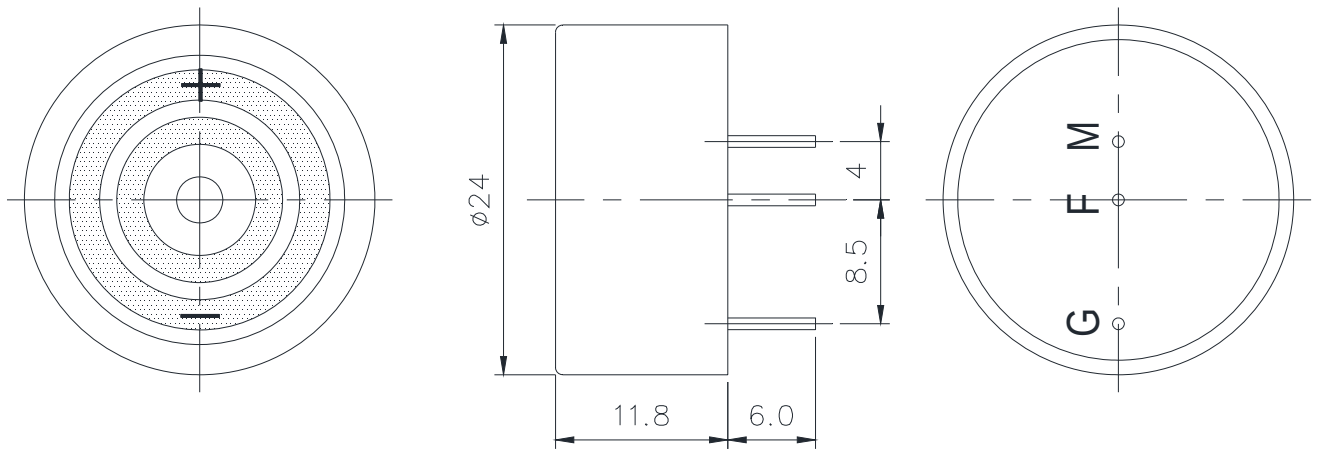

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Milton</i> *****		SCALE: 2:1	SHEET: 1 : 1
PART NO. <i>AZ-2430E-A</i>	1	DESIGNED: <i>R & D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>DTP-1165</i>		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>MPP0</i>		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2430E-A](#)