

1. SPECIFICATION

AZ-2220E-PU-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1 ~ 30	
03	Rated Current	mA(Max)	8	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	88	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	2000 ± 300	Rated Voltage
06	Capacitance	pF	20000±30%	At 120Hz
07	Operating Temp.	°C	-20 ~ +60	
08	Storage Temp.	°C	-30 ~ +70	
09	Weight	g	3	

REV NO.

REVISION NOTE

APPROVAL

DATE

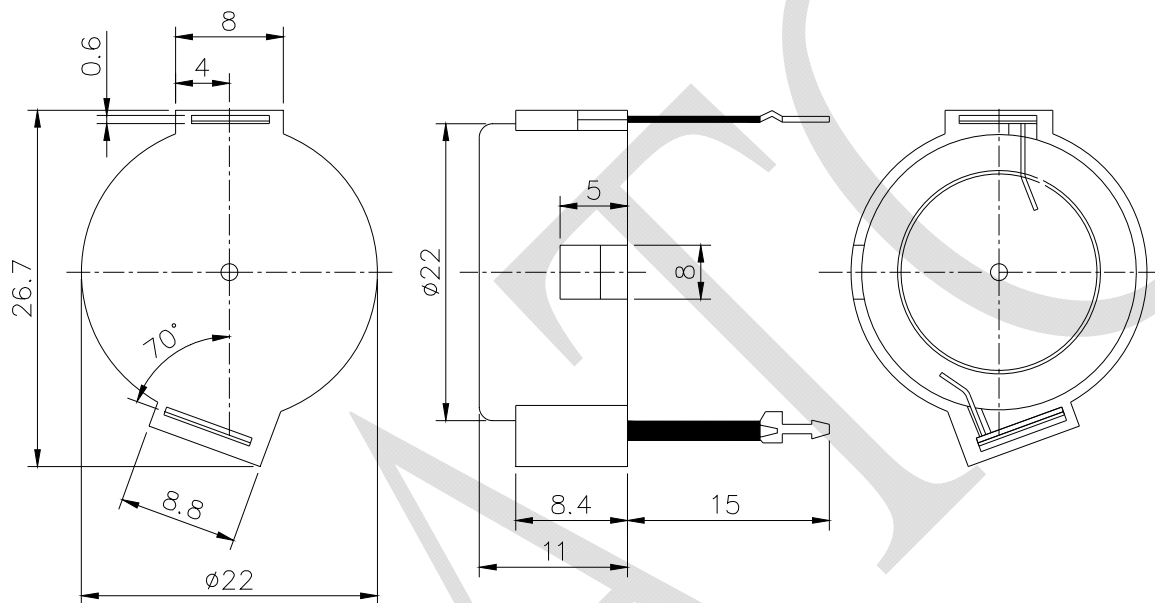

RoHS

TITLE: PIEZO BUZZER

DRAWN: Jack 2013/02/19

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-2220E-PU-LF

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. HS-090512

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***2
REV

MATERIAL: ABS



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-2240E-PU-LF