


1. SPECIFICATION

AR-150632A-2P

ITEM		SPECIFICATIONS
01	Type	Dynamic 15 x 6mm receiver unit
02	Sound pressure level	106 dB ±3 dB at 1KHz 179mV with IEC318 coupler.
03	Impedance	32 Ω±15% 1 KHz
04	Frequency Range	300 ~ 7 KHz
05	Rated Input Power	20m W
06	Max. Input Power	30m W
07	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.79m V
08	Operating temperature	-30℃ to +70℃
09	Storage temperature	-40℃ to +80℃
10	Weight	0.5g ± 0.2g

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

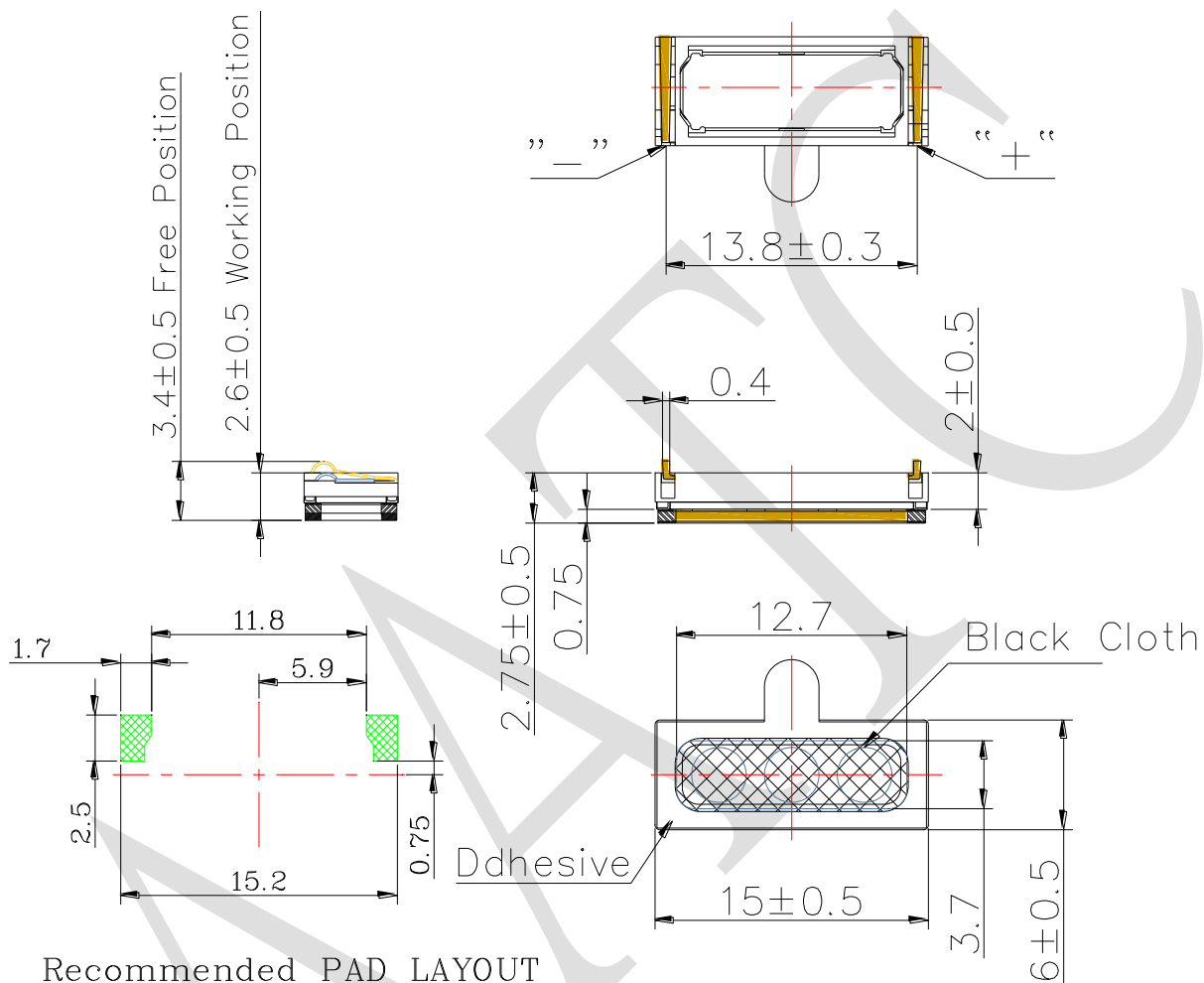

RoHS

TITLE: DYNAMIC RECEIVER		DRAWN: Moose	2015/09/02	SCALE: 4:1	SHEET: 1:1
PART NO. AR-150632A-2P	1	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. UGRP150632-16T-02		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: PPA	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AR-150632A-2P](#)