

1. SPECIFICATION

AZ-2844E-W1



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	6	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 25	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	80	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4400± 500	Rated Voltage
06	Capacitance	pF	25000±30%	At 1000Hz
07	Operating Temp.	℃	-20 ~ +70	
08	Storage Temp.	℃	-30 ~ +80	
09	Weight	g	2.5.	

REV NO.

REVISION NOTE

APPROVAL

DATE

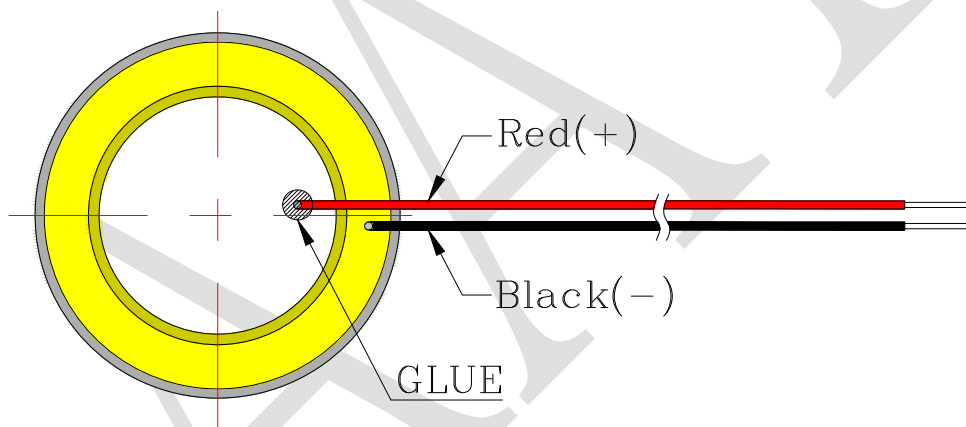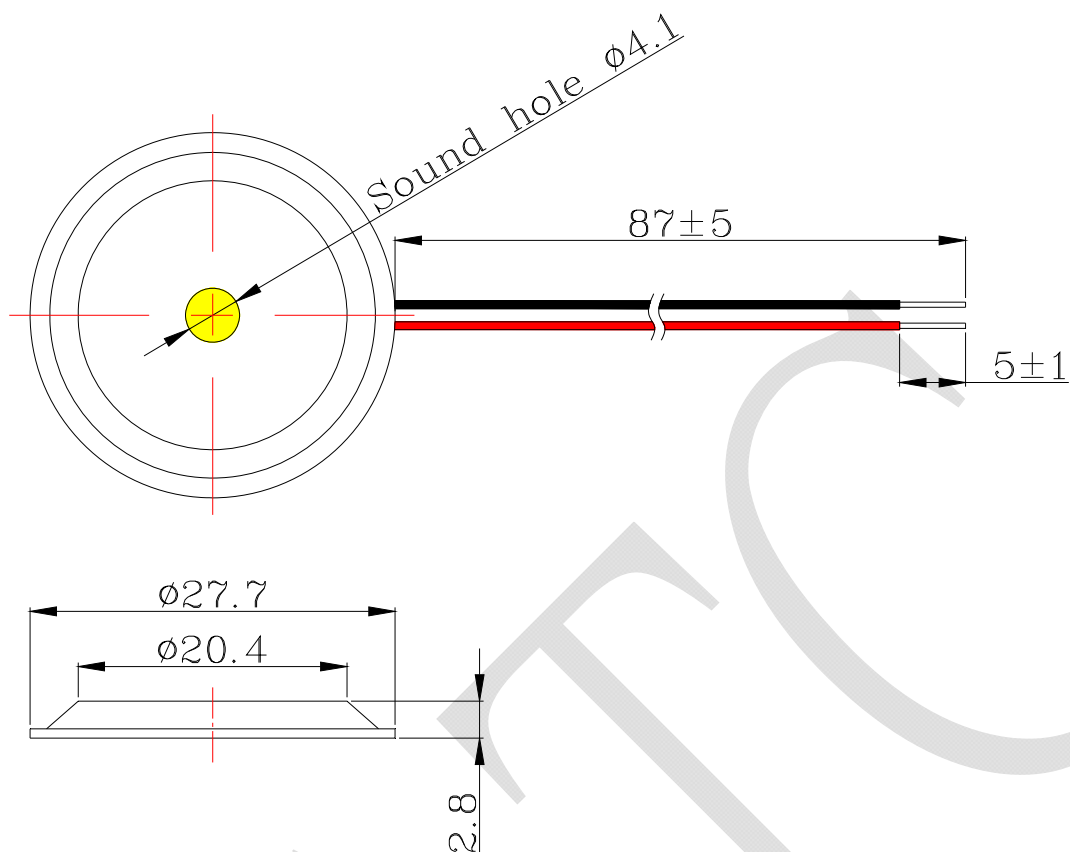

Wire: UL 1007.AWG 28#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Jerry</i> 2013/10/30	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-2844E-W1</i>	1	DESIGNED: <i>R&D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>BP2830W87-44</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>AL</i>	ONE PLACE DECIMAL \pm ***	
			TWO PLACE DECIMAL \pm ***	
			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-2844E-W1