


1. SPECIFICATION

AZ-3032S-P

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12.0	
02	Operating Voltage	VDC	3~20	
03	Rated Current	mA(Max)	10	
04	Sound Output At 10cm	dBA(Min)	90	
05	Resonant Frequency	Hz	3200±500	
06	Operating Temp.	℃	-20 ~ +60	
07	Storage Temp.	℃	-30 ~ +70	
08	Tone Nature	Single		
09	Weight	g	11	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

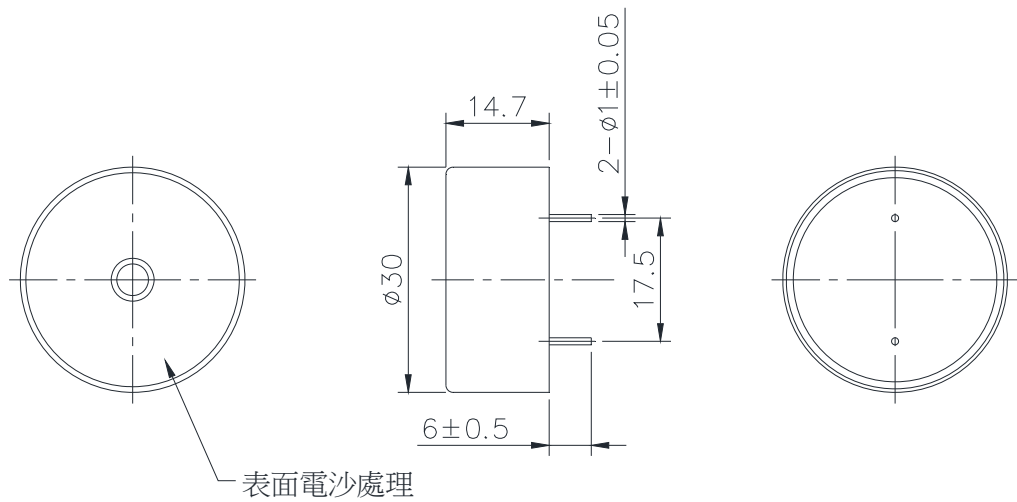

TITLE: <i>PIEZO BUZZER INDICATOR</i>		DRAWN: <i>Millon</i> 08/01/2001	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-3032S-P</i>	1	DESIGNED: <i>R & D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>DPT-1014</i>		CHECKED:	TOLERANCE ± 0.3	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-3032S-P](#)