
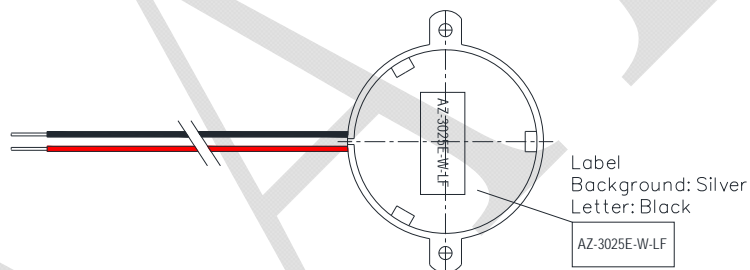


1. SPECIFICATION

AZ-3025E-W-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 30	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound Output (Distance at 10cm)	dBA(Min)	86	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	2500± 500	Rated Voltage
06	Capacitance	pF	25000±30%	At 1KHz
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	4.3	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

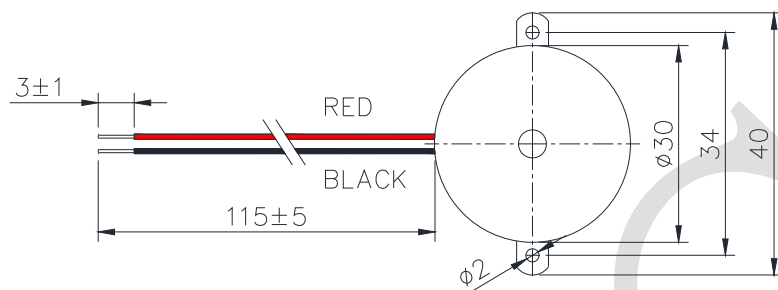

NOTE:
LEAD WIRES SPEC.: UL1095 AWG28

RoHS

TITLE:	PIEZO BUZZER	DRAWN:	Jason	2011/11/14	SCALE:	1:1	SHEET:	1 of 1
PART NO.	AZ-3025E-W-LF	DESIGNED:	R & D OF AAT		UNITS:	mm		
DWG NO.	DTP-1161	CHECKED:			TOLERANCE	± 0.5		
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:			
		MATERIAL:	ABS		ONE PLACE DECIMAL ± ***			
					TWO PLACE DECIMAL ± ***			
					THREE PLACE DECIMAL ± ***			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-3025E-W-LF