


1. SPECIFICATION



AZ-4229S-W

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3 ~ 28	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	2900	Rated Voltage
06	Resonant Frequency	Hz	2900 ± 500	
07	Tone Nature	Slow Pulse (1.2±30%Hz)		
08	Operating Temp.	℃	-20 ~ +60	
09	Storage Temp.	℃	-30 ~ +70	
10	Weight	g	15	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

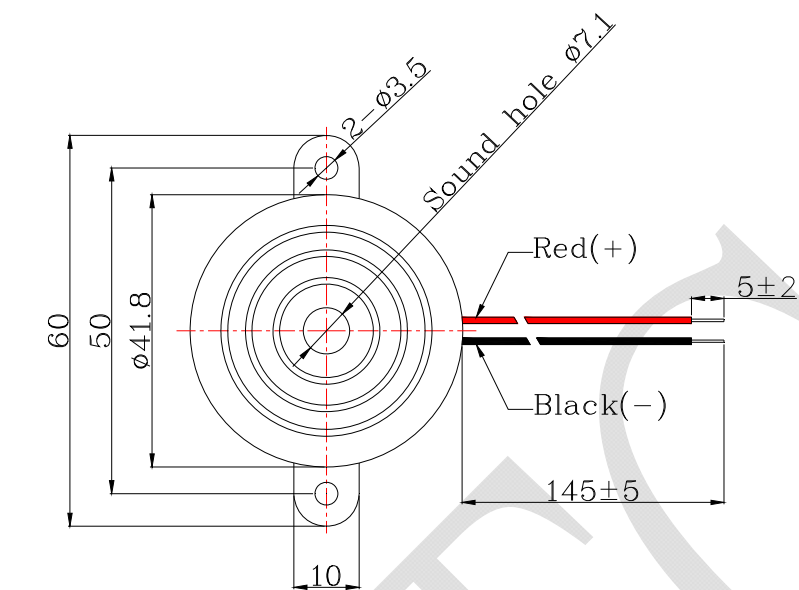

Wire: UL 1007.AWG28#

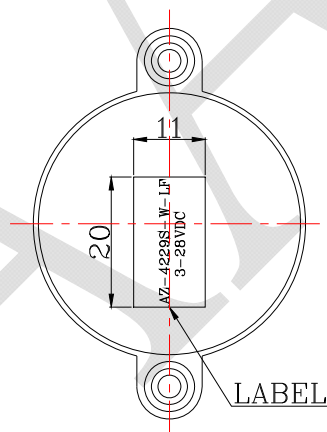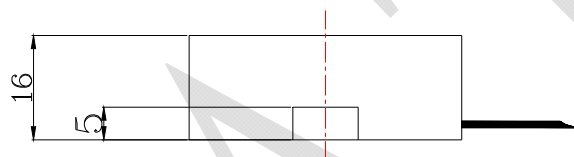

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Jack</i> 2015/08/04	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-4229S-W</i>	3	DESIGNED: <i>R & D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>UGPA42CX2912WS145</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL \pm ***	
			TWO PLACE DECIMAL \pm ***	
			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4229S-W