


1. SPECIFICATION

AD-403-PP




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 .0~ 4.3	
03	Consumption Current	mA (Max)	90	Standard state, standard drive circuit. Rated voltage, rated frequency, Square wave 1/2 duty.
04	Sound pressure level (Distance at 5 cm)	dB(A) (Min)	75	
	Sound pressure level (Distance at 10 cm)		65	
05	Direct Current Resistance	Ω	17 ± 3	
06	Rated Frequency	Hz	4000	
07	Operating Temp.	℃	-40 ~ +85	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	0.1	

REV NO.



REVISION NOTE

APPROVAL

DATE

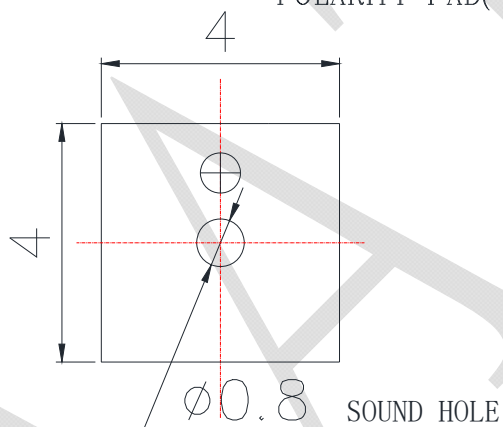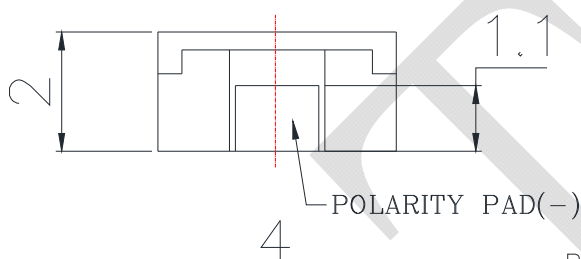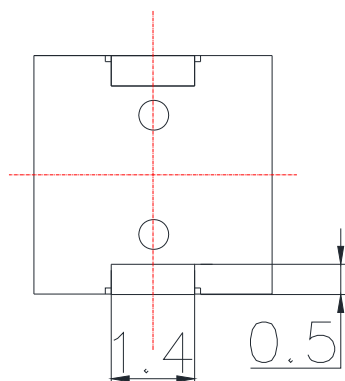

RECOMMENDED P.C.B LAYOUT

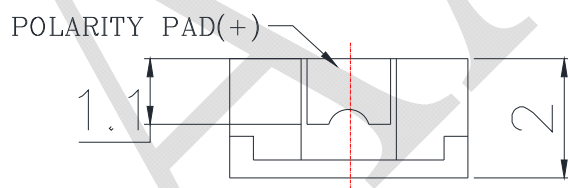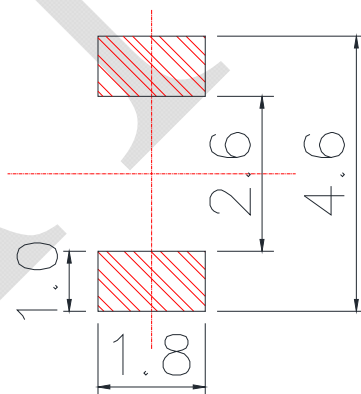

RoHS

TITLE: SOUND TRANSDUCER (SMD)

DRAWN: Sunny 2016/8/16

SCALE: 1:1

SHEET: 1 : 1

PART NO. AD-403-PP

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO. FDM-2859 SMD-040020F-03040

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

MATERIAL: LCP



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-403-PP](#)