


1. SPECIFICATIONS

AMB-O60S42-CC

SPECIFICATIONS		
01	Electret Type	BACK type
02	Sensitivity	-42±3dB (0dB=1V/Pa,1KHz)
03	Output Impedance (Max)	2.2K Ω
04	Directivity	Omnidirectional
05	Frequency Range	70-20,000Hz
06	Max.Operation Voltage	10V
07	Standard Operation Voltage	2.0V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0 to 1.5V
10	S/N Ratio	> 58dB
11	Operating Temperature	-25~+70°C
12	Storage Temperature	-40~+70°C

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

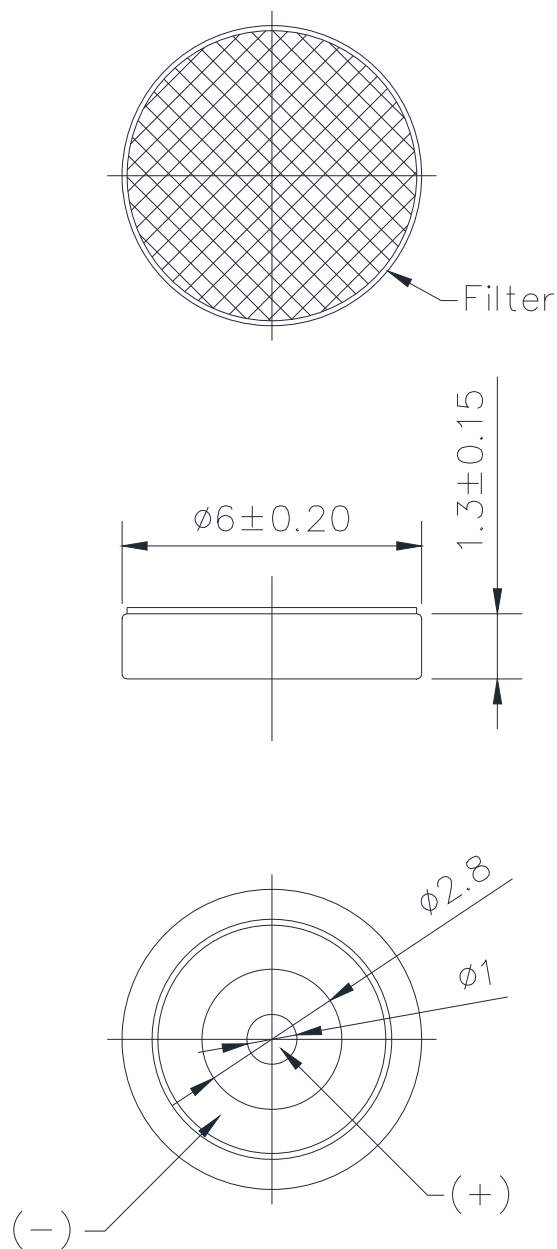

TITLE: MICROPHONE		1	DRAWN: JCHN 06/07/2004	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMB-060S42-CC			DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. DTM-1256			CHECKED:	TOLERANCE ± 0.2	
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV		MATERIAL: *****	ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AMB-O60S42-CC](#)