




1. SPECIFICATION

AR-1032A-1W

ITEM		SPECIFICATIONS
01	Type	Dynamic 10mm receiver unit
02	Sound pressure level	110 dB $\pm$ 3 dB at 1KHz 179mV with IEC318 coupler.
03	Impedance	32 Ω $\pm$ 15%
04	Frequency Range	300 ~ 3.4 K Hz
05	Rated Input Power	10 m W
06	Max. Input Power	20 m W
07	Total Harmonics Distortion	Max 10 % at 1 KHz,10 m W.
08	Operating temperature	-20°C to +60°C
09	Storage temperature	-30°C to +70°C
10	Weight	0.6g $\pm$ 0.2g

RoHS

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

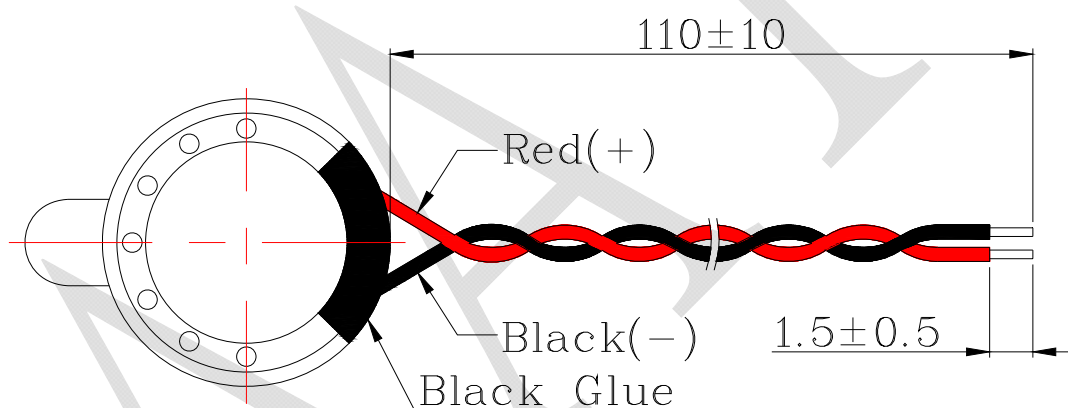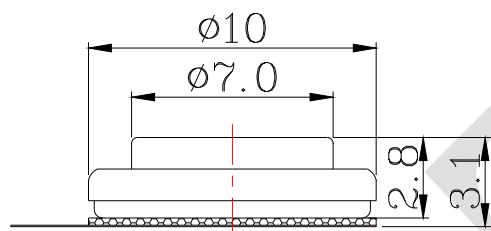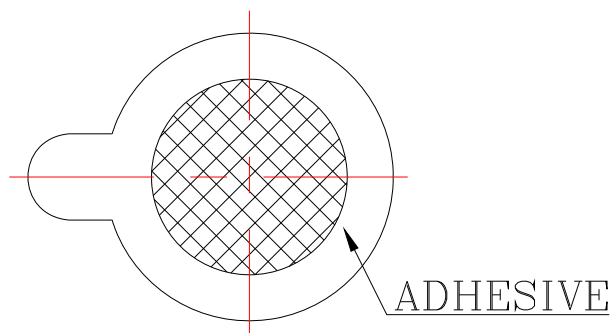

Wire: UL 1571. AWG32#

RoHS

TITLE: DYNAMIC RECEIVER		DRAWN: Jerry	2015/01/06	SCALE: 2:1	SHEET: 1:1
PART NO. AR-1032A-1W	1 REV	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. CXR10031L110-R32-A		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: SPCC	ONE PLACE DECIMAL ± ***		
			TWO PLACE DECIMAL ± ***		
			THREE PLACE DECIMAL ± ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AR-1032A-1W](#)