

1. SPECIFICATIONS

AMB-O60F42-NB1-LF




01	Electret Type	BACK type
02	Sensitivity	-42±3dB (0dB=1V/Pa,1KHz) Band form 300 to 3K Hz
03	Output Impedance (Max)	2.2K Ω
04	Directivity	Omnidirectional
05	Frequency Range	70-20,000Hz
06	Max.Operation Voltage	10V
07	Standard Operation Voltage	2.0V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0 to 1.5V
10	S/N Ratio	> 58dB
11	Operating Temperature	-20~+60°C
12	Storage Temperature	-30~+70°C

REV NO.

REVISION NOTE

APPROVAL

DATE

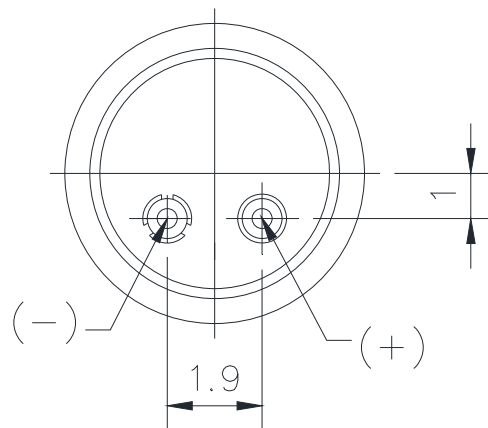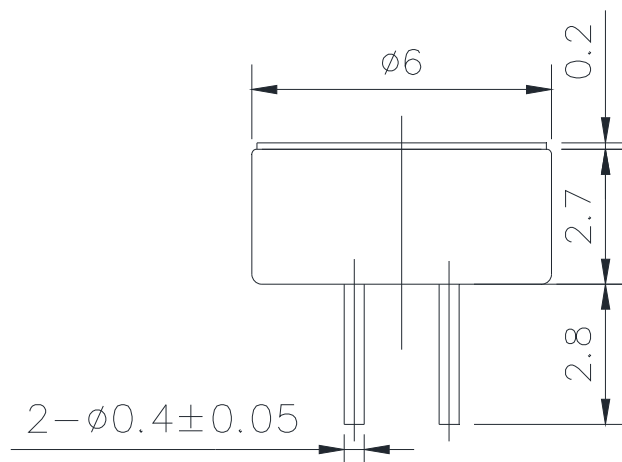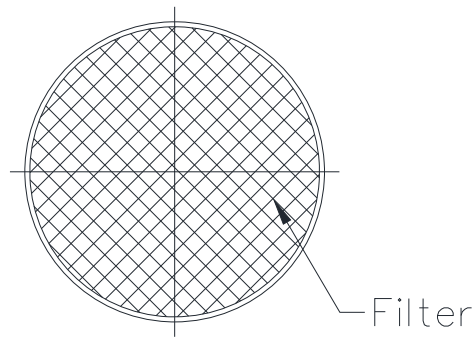

TITLE: MICROPHONE		1 REV	DRAWN: JCM 08/04/2006	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMB-060F42-NB1-LF			DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. DTM-1221			CHECKED:	TOLERANCE ± 0.2	
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
			MATERIAL: *****	ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMB-O60F42-NB1-LF](#)