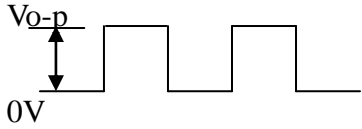


## 1. SPECIFICATION

AS-1201E-RPA


Items		Units	Specifications				Conditions
01	Rated Voltage	Vo-p	1.5				
02	Operating Voltage	Vo-p	1.0~2.0				
03	Mean Current	mA (Max)	70				Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
04	Direct Current Resistance	Ohm	$6.5 \pm 1.0$				
05	Sound Output	dBA (min)	80				Distance at 10cm, applying rated voltage, rated frequency square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	$2048 \pm 200$				
07	Operating Temp.	°C	-40 ~ +85				
08	Storage Temp.	°C	-50 ~ +95				
09	Dimension	mm	Φ	12.0	Height	7.5	See attached drawing.
10	Weight	Gram	2.0				
11	Terminal		Two Pins				See attached drawing.

REV NO.

REVISION NOTE

APPROVAL

DATE

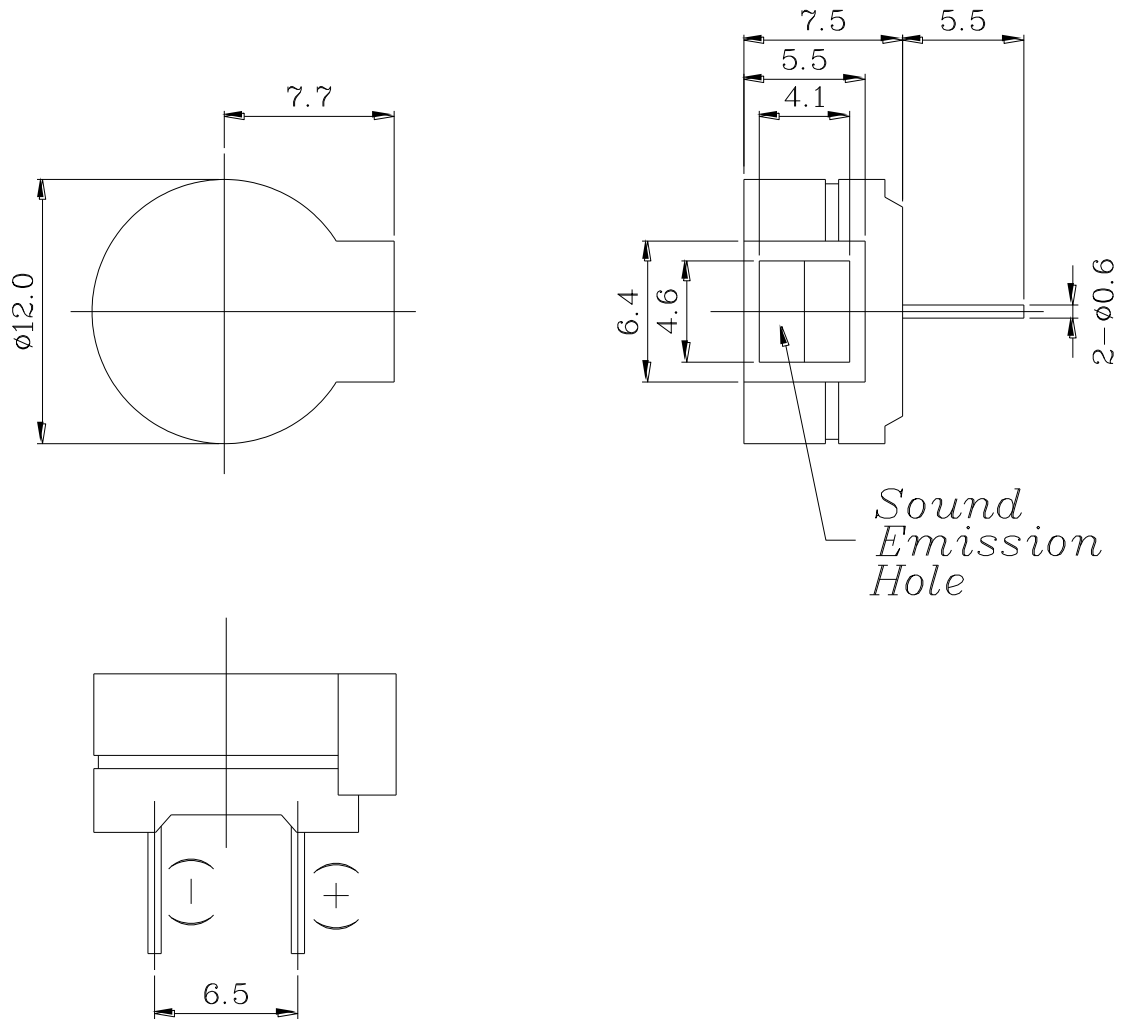

Sound  
Emission  
Hole

TITLE: SOUND TRANSDUCER DIMENSIONS

DRAWN: Sea 02/01/2000

SCALE: 3/1 SHEET: 1 OF 1

PART NO. AS-1201E-RPA

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

DWG NO. DTE-1020

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

REV

MATERIAL: PPO



苙翔科技股份有限公司  
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AS-1201E-RPA](#)