


1. SPECIFICATION**AB-2317121-W(RoHS)**

Items		Units	Specifications	Conditions
1	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	9~15	
03	Mean Current	mA (Max)	25	Applying rated voltage,
04	Sound Output	dBa (min)	75	Distance at 20cm,applying rated
05	Tone Nature	single		
06	Resonant Frequency	Hz	400 ± 100	
07	Operating Temp.	°C	-10 ~ +60	
08	Storage Temp.	°C	-10 ~ +70	
09	Weight	Gram	10	
11	Terminal	Lead wire/lead pin material		AWG26# UL1095 Lead Wire

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

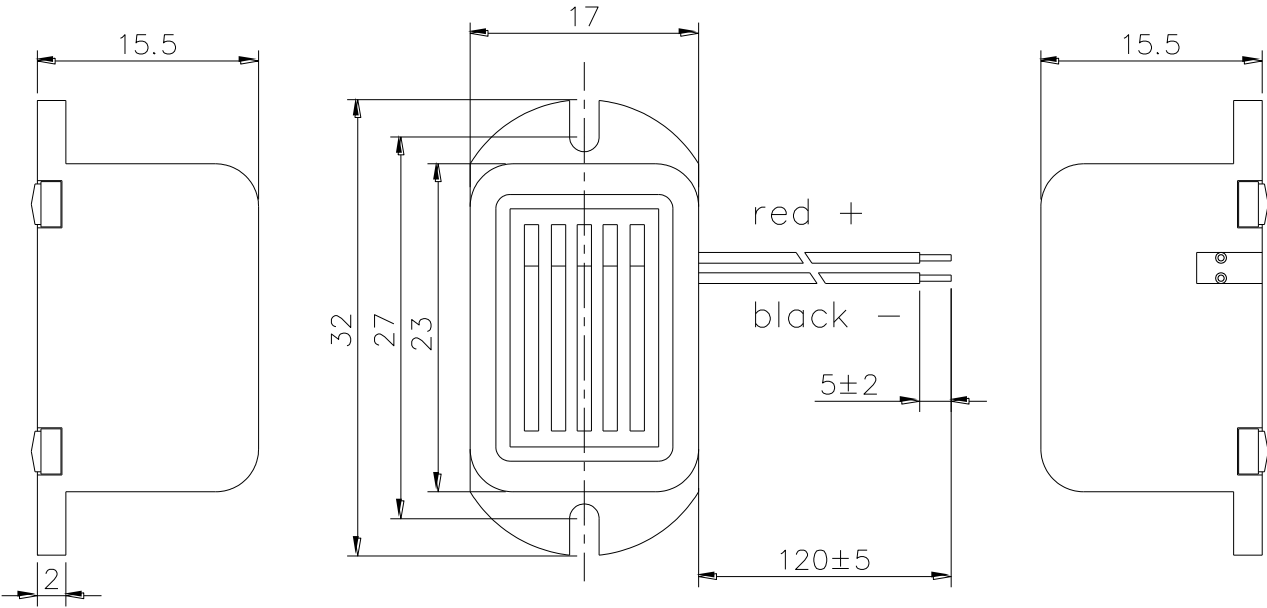

TITLE: SOUND TRANSDUCER DIMENSIONS		DRAWN: Milton	05/17/2001	SCALE: 2/1	SHEET: 1 OF 1
PART NO. AB-2317121-W	1	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. DTB-1001		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: ABS	ONE PLACE DECIMAL ± ***		
			TWO PLACE DECIMAL ± ***		
			THREE PLACE DECIMAL ± ***		



苙翔科技股份有限公司
 ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AB-2317121-W](#) [AB-2317241-W](#)