
 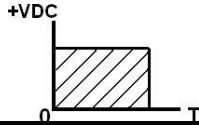



1. SPECIFICATION

AX-12Q24C

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	24	
02	Operating Voltage	V	20 ~ 28	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	2600 ± 200	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage / Resonant Frequency
07	Operating Temp.	℃	-30 ~ +70	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	2	

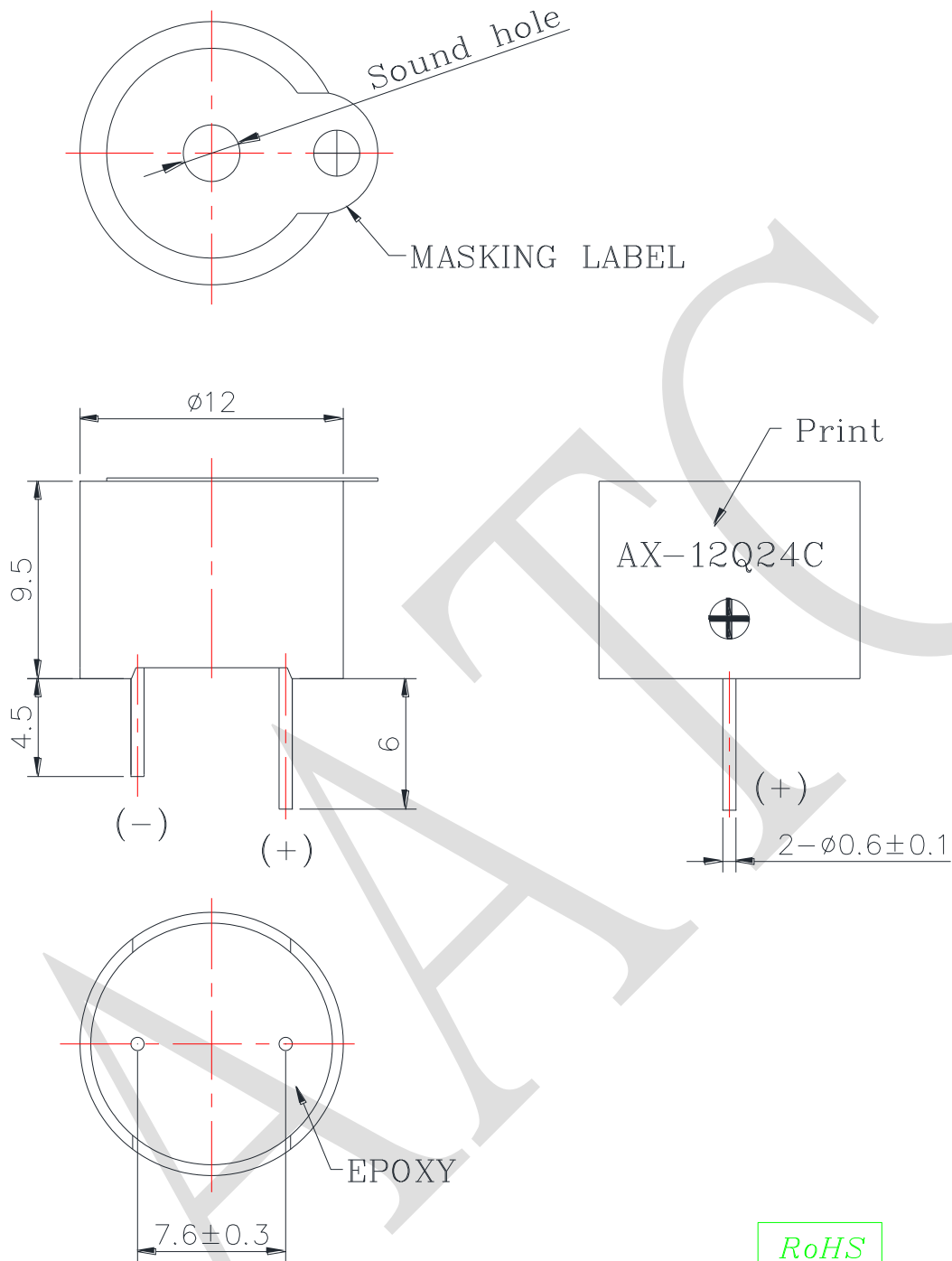

TITLE: ELECTRO MAGNETIC INDICATOR		DRAWN: Zack	2020/08/27	SCALE: 4:1	SHEET: 1 of 1
PART NO. AX-12Q24C		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. ****-*****		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		FIRST ANGLE PROJECTION	
REV		MATERIAL: PBT			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-12Q24C](#)